


WAD 5 MC B GE/SW**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

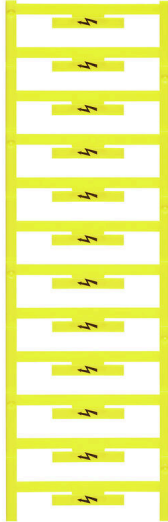

The WAD connector marker is suitable for W-series terminals and for the WEW 35/2 and ZEW 35/2 end brackets. The markers are available as blank markers, with custom printing or standard print with lightning symbol. The WAD MultiCard markers are suitable for labelling with PrintJet CONNECT printers. For custom printing: Please send us a file of our labelling software M-Print PRO or M-Print PRO Online (without installation) for your labelling specifications.

General ordering data

| | |
|------------|--|
| Version | Group markers, Cover, 33.3 x 5 mm, Pitch in mm (P): 5.00 WDU 2.5, WEW 35/2, ZEW 35/2, yellow |
| Order No. | 1120450000 |
| Type | WAD 5 MC B GE/SW |
| GTIN (EAN) | 4032248901272 |
| Qty. | 48 items |

WAD 5 MC B GE/SW

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 11.74 mm | Depth (inches) | 0.4622 inch |
| Height | 33.3 mm | Height (inches) | 1.311 inch |
| Width | 5 mm | Width (inches) | 0.1968 inch |
| Net weight | 1.44 g | | |

Temperatures

Operating temperature range -40...100 °C

Environmental Product Compliance

| | | | |
|--------------------------|-----------------------------|------------------|--|
| RoHS Compliance Status | Compliant without exemption | | |
| REACH SVHC | No SVHC above 0.1 wt% | | |
| Product Carbon Footprint | Cradle to gate | 0.085 kg CO2 eq. | |

General data

| | | | |
|--|-----------------------------|-----------|--|
| Material colour according to resistance code | 4 | | |
| Type of printing | Symbols | | |
| Width | 5 mm | | |
| UL 94 flammability rating | V-2 | | |
| Operating temperature range, max. | 100 °C | | |
| Operating temperature range, min. | -40 °C | | |
| Colour | yellow | | |
| Halogen | No | | |
| Basic material | Polyamide 66 | | |
| Colour of printing | black | | |
| Printed characters | Symbols | | |
| Number of markers per packaging unit | Form of supply | MultiCard | |
| Number of markers per combination | 1 MultiCard = Cover | | |
| Operating temperature range | -40...100 °C | | |
| Application/manufacturer | WDU 2.5, WEW 35/2, ZEW 35/2 | | |

Connector markers

Pitch in mm (P) 5.00 mm

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000761 | ETIM 9.0 | EC000761 |
| ETIM 10.0 | EC000761 | ECLASS 14.0 | 27-28-11-01 |
| ECLASS 15.0 | 27-28-11-01 | | |



Drawing

