


**BG GH 10P 4XVG PT6****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

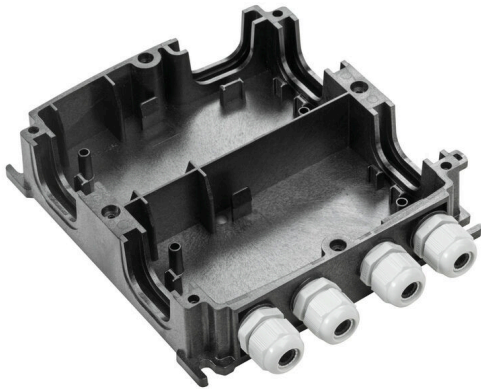

The FieldPower® housings are highly robust and meet the highest UL flammability class 5 VA.

- The "TS 35 PT6" mounting rail module and PT6 contact unit are easy to snap on.
- Hinged seals allow pre-assembled plug cables to also be used.
- The high cover versions enable the device to be installed.

For cable seals consult accessories.

**General ordering data**

Version	FieldPower® enclosures, 181 mm, 223 mm, 42 mm, IP65, in complete state, glass-fibre reinforced polycarbonate, black
Order No.	<a href="#">1121990000</a>
Type	BG GH 10P 4XVG PT6
GTIN (EAN)	4032248903030
Qty.	10 items

**BG GH 10P 4XVG PT6**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UL)	E256877

**Dimensions and weights**

Depth	42 mm	Depth (inches)	1.6535 inch
Height	181 mm	Height (inches)	7.126 inch
Width	223 mm	Width (inches)	8.7795 inch
Net weight	367 g		

**Temperatures**

Storage temperature	-40 °C...85 °C	Operating temperature	-20 °C...80 °C
---------------------	----------------	-----------------------	----------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	210f646e-64fd-46de-9a7c-8dff222ea2cb

**Cable gland**

Number of cable glands	4	Cable gland clamping area, min.	6 mm
Cable gland material	Polyamide 6	Cable gland clamping area, max.	12 mm

**General data**

Basic material	Plastic, GRP	Enclosure material	glass-fibre reinforced polycarbonate
Silicone	No	Colour	black
Protection degree	IP65, in complete state	UL 94 flammability rating	5VA
Type of mounting	Screw mounting, Fixing lugs	With cable gland	Yes

**Classifications**

ETIM 8.0	EC000261	ETIM 9.0	EC000261
ETIM 10.0	EC000261	ECLASS 14.0	27-18-01-01
ECLASS 15.0	27-18-01-01		

**BG GH 10P 4XVG PT6**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

**Drilling template**

