


**PF RS 122 OR 2000MM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

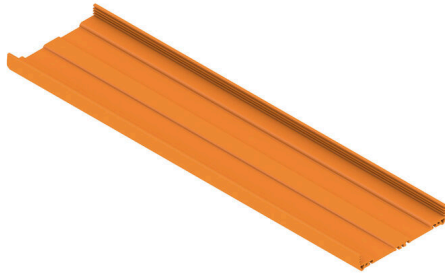

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

**General ordering data**

Version	Profile housing, OMNIMATE Housing - RS orange, Extruded profile, Width: 2000 mm
Order No.	<a href="#">1155940000</a>
Type	PF RS 122 OR 2000MM
GTIN (EAN)	4032248942572
Qty.	2 M

## PF RS 122 OR 2000MM

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	22 mm	Depth (inches)	0.8661 inch
Height	127 mm	Height (inches)	5 inch
Width	2000 mm	Width (inches)	78.74 inch
Net weight	750 g		

### Temperatures

Operating temperature	-15 °C...40 °C
-----------------------	----------------

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Material data

UL 94 flammability rating	V-0	Insulating material	PVC
Surface finish	untreated	Basic material	PVC

### General data

Colour	orange	Protection degree	IP20 in installed state
Colour chart (similar)	RAL 2000	Encapsulation option	No


### Important note

Product information	2 optional positions for the PCB Dimensions of the PCB: Thickness: 1.6 (±0.2) mm, width: 122 (+0.5) mm Dimension of RS section = PCB length - 5 mm Example: PCB length 160 mm, RS section = 155 mm
---------------------	---

### Classifications

ETIM 8.0	EC002779	ETIM 9.0	EC002779
ETIM 10.0	EC002779	ECLASS 14.0	27-19-06-01
ECLASS 15.0	27-19-06-01		

 **Drawings**



## PF RS 122 OR 2000MM

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### AP RF 122 LI - End plate DIN rail mounting left side




The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

#### General ordering data

Type	AP RF 122 LI OR 2000	Version	
Order No.	<a href="#">1020640000</a>	End plate orange, End plate DIN mounting rail left incl. fixing screws,	
GTIN (EAN)	4032248740178	Width: 6.4 mm	
Qty.	20 ST		

### AP RF 122 RE - End plate DIN rail mounting right side

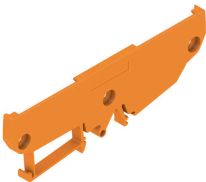

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

#### General ordering data

Type	AP RF 122 RE OR 2000	Version	
Order No.	<a href="#">1020650000</a>	End plate orange, End plate DIN mounting rail right incl. fixing screws,	
GTIN (EAN)	4032248740161	Width: 6.4 mm	
Qty.	20 ST		


## PF RS 122 OR 2000MM

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### RF 108 - Clip-in foot

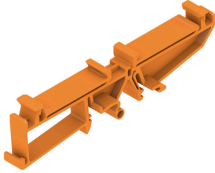

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

### General ordering data

Type	RF 108 OR 2000	Version	
Order No.	<a href="#">1020690000</a>	Clip-in foot, RS 80, RS 90, RS 100 orange, Clip-in foot, Width: 17.5	
GTIN (EAN)	4032248740154	mm	
Qty.	20 ST		