

**RIM 5 6/230VDC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With free-wheeling diode or RC filter

**General ordering data**

Version	D-SERIES, Free-wheeling diode, Rated control voltage: 6...230 V DC, Plug-in connection
Order No.	<a href="#">1174650000</a>
Type	RIM 5 6/230VDC
GTIN (EAN)	4032248971305
Qty.	10 items

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (cURus)	E312083

**Dimensions and weights**

Depth	44 mm	Depth (inches)	1.7323 inch
Height	10 mm	Height (inches)	0.3937 inch
Width	35 mm	Width (inches)	1.378 inch
Net weight	5.3 g		

**Temperatures**

Storage temperature	Operating temperature
---------------------	-----------------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Rated data UL**

Certificate No. (cURus)	E312083
-------------------------	---------

**Control side**

Rated control voltage	6...230 V DC	Status indicator	No
Protective circuit	Free-wheeling diode		

**General data**

Colour	black		
UL94 flammability rating component	Component	Housing	
	UL94 flammability rating	V-2	

**Further details of approvals / standards**

Certificate No. (CSA)	80107692	Certificate No. (cURus)	E312083
-----------------------	----------	-------------------------	---------

**Connection data**


Wire connection method	Plug-in connection
------------------------	--------------------

**Classifications**

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		

**Drawings**

**Wiring diagram**

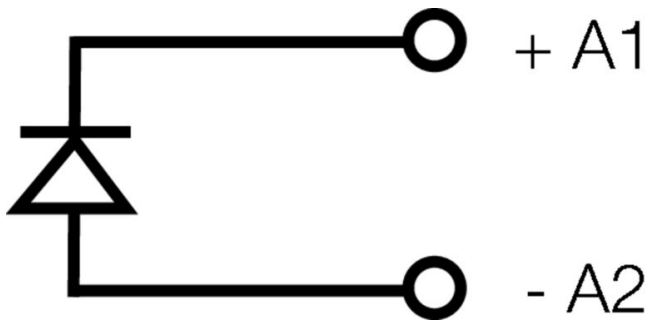

**Dimensional drawing**

