 
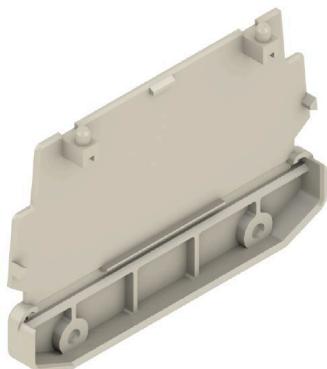


AP 110 D GY**Weidmüller Interface GmbH & Co. KG**Klingenbergsstraße 26
D-32758 Detmold
Germanywww.weidmueller.com

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation. Another practical feature is the option of using a cover profile to protect large components.

General ordering data

| | |
|------------|-----------------------------------------------------------------------------------|
| Version | End plate, RS 100 Pebble grey, End plate direct mounting both sides, Width: 22 mm |
| Order No. | 1188660000 |
| Type | AP 110 D GY |
| GTIN (EAN) | 4032248972616 |
| Qty. | 10 items |

AP 110 D GY

Weidmüller Interface GmbH & Co. KG
 Klingenbergsstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| RoHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 71.7 mm | Depth (inches) | 2.8228 inch |
| Height | 109.5 mm | Height (inches) | 4.311 inch |
| Width | 22 mm | Width (inches) | 0.8661 inch |
| Net weight | 16.41 g | | |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Material data

| | | | |
|----------------------------------|-----------|---------------------------|-------|
| UL 94 flammability rating | V-2 | Insulating material group | I |
| Surface finish | untreated | Basic material | PA 66 |
| Comparative Tracking Index (CTI) | 600 ≤ CTI | | |

General data

| | | | |
|------------------------|-------------|-------------------|-------------------------|
| Colour | Pebble grey | Protection degree | IP20 in installed state |
| Colour chart (similar) | RAL 7032 | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001031 | ETIM 9.0 | EC002779 |
| ETIM 10.0 | EC002779 | ECLASS 14.0 | 27-19-06-02 |
| ECLASS 15.0 | 27-19-06-02 | | |

AP 110 D GY

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

DIRECT MOUNTING
FOR BOTH SIDES (RIGHT AND LEFT)

