

**AP 111 D BK****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

**General ordering data**

Version	End plate, RS 100 black, End plate direct mounting both sides, Width: 22 mm
Order No.	<a href="#">1189880000</a>
Type	AP 111 D BK
GTIN (EAN)	4050118159929
Qty.	10 items

**AP 111 D BK**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	101.7 mm	Depth (inches)	4.0039 inch
Height	108.6 mm	Height (inches)	4.2756 inch
Width	22 mm	Width (inches)	0.8661 inch
Net weight	8 g		

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Material data**

UL 94 flammability rating	V-2	Insulating material	PA 66
Insulating material group	I	Surface finish	untreated
Basic material	PA 66	Comparative Tracking Index (CTI)	600 ≤ CTI

**General data**

Colour	black	Protection degree	IP20 in installed state
Colour chart (similar)	RAL 9011	Encapsulation option	No

**Classifications**

ETIM 8.0	EC001031	ETIM 9.0	EC002779
ETIM 10.0	EC002779	ECLASS 14.0	27-19-06-02
ECLASS 15.0	27-19-06-02		


AP 111 D BK


Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

Drawings

www.weidmueller.com

DIRECT MOUNTING  
FOR BOTH SIDES (RIGHT AND LEFT)

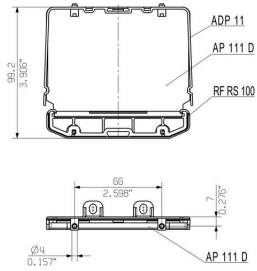

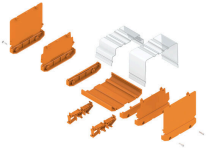**RS 100 - Profile housing**

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

**General ordering data**

Type	PTSC KB40X14	Version
Order No.	<a href="#">4019420000</a>	Mounting screw (Terminal), 0.00 mm, Steel, Depth: 7 mm, Width:
GTIN (EAN)	4008190243029	16.9 mm, Height: 7 mm
Qty.	100 ST	