

HDC 10B ABU

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | |
|------------|--|
| Version | HDC enclosures, Installation size: 4, Protection degree: IP65, in plugged condition, Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard, Size of cable entries: none |
| Order No. | 1205000000 |
| Type | HDC 10B ABU |
| GTIN (EAN) | 4008190872960 |
| Qty. | 1 items |

Technical data

Approvals

Approvals



| | |
|-------------------------|----------------------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate No. (cURus) | E92202 |

Dimensions and weights

| | | | |
|-----------------------------|---------|----------------------------|-------------|
| Height | 29.3 mm | Height (inches) | 1.1535 inch |
| Width | 55 mm | Width (inches) | 2.1654 inch |
| Mounting dimension - height | 32 mm | Mounting dimension - width | 83 mm |
| Net weight | 146 g | | |

Temperatures

| | |
|-------------------|-------------------|
| Limit temperature | -40 °C ... 125 °C |
|-------------------|-------------------|

Environmental Product Compliance

| | |
|------------------------|--|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | Potassium perfluorobutane sulfonate 29420-49-3 |
| SCIP | e98b2b24-ba23-41bf-8d19-0dda3647412f |

| | | |
|---------------------|---------------------|-------------------------|
| Chemical resistance | Substance | Acetone |
| | Chemical resistance | Conditionally resistant |
| | Substance | Drilling oil |
| | Chemical resistance | Resistant |
| | Substance | Diesel |
| | Chemical resistance | Resistant |
| | Substance | Ethyl alcohol |
| | Chemical resistance | Resistant |
| | Substance | Transmission oil |
| | Chemical resistance | Resistant |
| | Substance | Hydraulic oil |
| | Chemical resistance | Resistant |
| | Substance | Coolant |
| | Chemical resistance | Resistant |
| | Substance | Petroleum benzene |
| | Chemical resistance | Resistant |
| | Substance | Sweat |
| | Chemical resistance | Resistant |
| | Substance | Premium gasoline |
| | Chemical resistance | Conditionally resistant |
| Substance | Water | |
| Chemical resistance | Resistant | |
| Substance | UV | |
| Chemical resistance | Unstable | |
| Substance | Ozone | |
| Chemical resistance | Unstable | |

Dimensions

| | | | |
|----------------------|-------|---------------|-------|
| Hole pitch length A2 | 83 mm | Cable entry | No |
| Width housing C | 43 mm | Width base C1 | 47 mm |

HDC 10B ABU

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

| | | | |
|----------------------|--------|---------------------|-------|
| Total length housing | 73 mm | Height of housing B | 30 mm |
| Height of base B1 | 5.3 mm | | |

General data

| | | | |
|-----------------------------|-----------------------------|----------------|----------------|
| Housing main material | diecast aluminium | Surface finish | Powder coating |
| Protection degree | IP65, in plugged condition | EMC housings | No |
| Material of locking element | Stainless steel, rust-proof | | |

Version

| | | | |
|--------------------------------|--|------------------------|--------------------|
| Number of cable glands | 0 | Size of cable entries | none |
| Top part/bottom part/lid | lower part | Cover | without cover |
| Number of cable entry sideways | 0 | Design of housing | Bulkhead housing |
| Design of locking system | Side-locking clamp on lower side, Side-locking clamp not replaceable | Design | Standard |
| Installation size | 4 | Cable entry | No |
| Type | Bulkhead (feed-through) | Clamp version | Side-locking clamp |
| Sealing | NBR | Colour (RAL) | RAL 7035 |
| BG | 4 | Suitable for ModuPlug® | Yes |


Important note

| | |
|---------------------|---|
| Product information | When mounting the housings, make sure that the flat gasket is correctly seated. |
|---------------------|---|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000437 | ETIM 9.0 | EC000437 |
| ETIM 10.0 | EC000437 | ECLASS 14.0 | 27-44-02-02 |
| ECLASS 15.0 | 27-44-02-02 | | |

Drawings

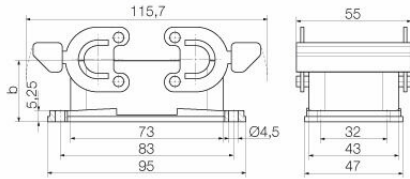

Accessories

Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | HDC 10B DODQ 4B0 | Version | |
| Order No. | 1665230000 | | |
| GTIN (EAN) | 4008190421939 | | |
| Qty. | 1 ST | | |