

IE-PS-SCRJ1-POF


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

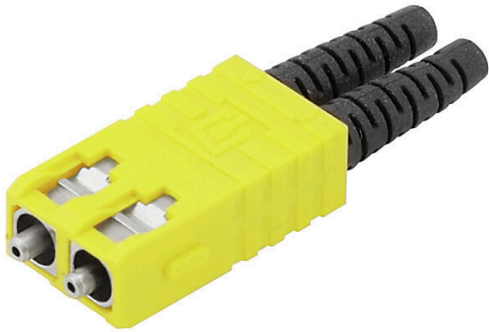

FO SC-RJ plug-in connectors according to IEC 61754-24
for wire outer diameters 2.6 to 3 mm

General ordering data

Version	FO connector, Plug SCRJ, POF, IP20
Order No.	1206720000
Type	IE-PS-SCRJ1-POF
GTIN (EAN)	4032248988570
Qty.	10 items

IE-PS-SCRJ1-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (UL) E477798

Dimensions and weights

Depth	51 mm	Depth (inches)	2.0079 inch
Height	14.7 mm	Height (inches)	0.5787 inch
Width	8.95 mm	Width (inches)	0.3524 inch
Net weight	10 g		

Temperatures

Storage temperature	Operating temperature	-20 °C...80 °C
Installation temperature	Humidity	0...93 % rel. humidity

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

General data

Bending protection sleeve material	TPE	Description of article	Plug SCRJ, POF
Colour	yellow, black	Housing main material	PC UL 94 V0
Humidity	0...93 % rel. humidity	Protection degree	IP20
Plugging cycles	1000	Fibre type	POF
Insertion loss	≤ 1.0 dB	Connection 1	SCRJ
Connection 2	Rapid connection system: crimping, cutting	Cable pull-out force, min.	100 N
Single conductor diameter, min	2.1 mm	Housing material, insert	Zinc diecast, nickel-plated
Pressure spring material	Stainless steel, rust-proof	Ferrule material	Nickel silver
Dust protection cap material	TPE	Single conductor diameter, max	2.3 mm
Crimp barrel material	Copper, nickel-plated		

General standards

Connector standard	IEC 61754-24	Certificate No. (UL)	E477798
--------------------	--------------	----------------------	---------

Classifications

ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		


IE-PS-SCRJ1-POF

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensioned drawing

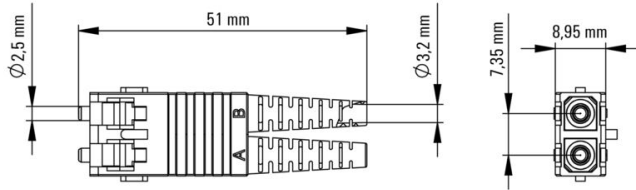

IE-PS-SCRJ1-POF

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

SC-RJ



FO SC-RJ plug-in connectors according to IEC 61754-24 for wire outer diameters 2.6 to 3 mm

General ordering data

Type	IE-SCRJ1-IP20-POF-100	Version	
Order No.	1278420000	FO connector, Replacement crimp barrel, IP20	
GTIN (EAN)	4050118069129		
Qty.	100 ST		

...for fibre-optic cable with polymer optical fibres (POF)



Crimping and stripping tools for processing the fibre-optic-cable contacts of polymer optical fibres (POF)

General ordering data

Type	HTX-IE-POF	Version	
Order No.	1208870000	Pressing tool	
GTIN (EAN)	4032248990269		
Qty.	1 ST		

Contact removal tools



Weidmüller offers a variety of crimping tools, contact removal tools, and fibre optic tools.

General ordering data

Type	REMOVAL TOOL HD	Version	
Order No.	1866730000	Tools, Contact Removal Tool	
GTIN (EAN)	4032248437054		
Qty.	1 ST		