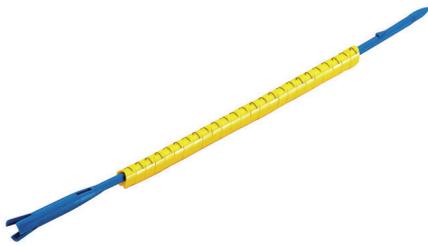


CLI R 1-15 GN CLOSE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

The CableLine range of wire and cable marker products provides users with solutions for the most diverse applications. The range of applications extends from narrow wires right up to cables with large outside diameters.

General ordering data

Version	CableLine, Mounting mandrel
Order No.	1208950000
Type	CLI R 1-15 GN CLOSE
GTIN (EAN)	4032248990344
Qty.	10 items

CLI R 1-15 GN CLOSE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	5 mm	Depth (inches)	0.1968 inch
Height	3 mm	Height (inches)	0.1181 inch
Width	4.2 mm	Width (inches)	0.1654 inch
Net weight	1.85 g		

Temperatures

Operating temperature range -30...80 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Orientation of print	horizontal	Type of printing	To customer specification
Printing method	Ink jet technology	Version	MultiPack
Width	4.2 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	80 °C	Operating temperature range, min.	-30 °C
Colour	To customer specification	Halogen	Yes
Basic material	PVC, soft, without Cadmium	Colour of printing	black
Printed characters	Mixed characters	Number per mandrel	5
Operating temperature range	-30...80 °C		

Conductor and cable markers

Halogen	Yes	Conductor cross-section, max.	4 mm ²
Conductor cross-section, min.	1.5 mm ²	Conductor O.D., max.	5 mm
Conductor O.D., min.	2.5 mm	Conductor O.D.	2.5 - 5 mm
Cross-section for connected wire	1.5 - 4 mm ²		

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		