

VP M40 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	VPMS Ex (ex blanking plug, brass), Blanking plug, straight, M 40, 15 mm, Brass, nickel-plated
Order No.	1210930000
Type	VP M40 EXE MS
GTIN (EAN)	4032248992430
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2024-08-31T00:00:00+02:00
Alternative product	VP-HEX M40-EX W

VP M40 EXE MS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	19 mm	Height (inches)	0.748 inch
Length	19 mm	Length (inches)	0.748 inch
Diameter	40 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	14 mm	Net weight	115.2 g

Temperatures

Operating temperature	-40 °C...100 °C
-----------------------	-----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, Imidazolidine-2-thione 96-45-7
SCIP	4efa9808-c72a-4b94-8dcb-498465ba8c6e

Certificate numbers cable gland

Identification	II 2 GD, Ex d IIC, Ex e II, Ex tD	Certificate no. cable gland (ATEX)	INERIS 09 ATEX 0059X
----------------	-----------------------------------	------------------------------------	----------------------

General information

O-Ring	NBR	Silicone	No
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Pitch of thread	1.5 mm	Halogen	Yes
AF size 1	45 mm	Protection degree	IP54, IP64, IP68
Basic material	Brass, nickel-plated	Diameter of sealing ring	40.00 mm
External thread	M 40	Length of thread	15 mm
Torque for cap nut, max.	13.20 Nm	Torque for connecting adapter, max.	44.00 Nm
Torque for connecting adapter, min.	22.00 Nm	Torque for cap nut, min.	8.80 Nm

Classifications


ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		

VP M40 EXE MS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

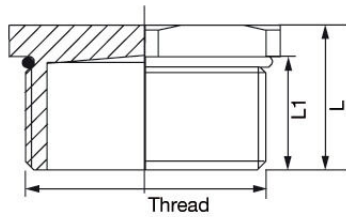

VP M40 EXE MS
Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com
Accessories
Brass lock nuts, nickel-plated


In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU M40 MS	Version
Order No.	1737030000	SKMU MS (brass locknut), Locknut, M 40, 5 mm, Brass, nickel-plated
GTIN (EAN)	4008190956509	
Qty.	50 ST	

Neoprene flat gasket - GWDR NP


In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M40-NP	Version
Order No.	1736270000	GWDR NP (flat gasket - neoprene), Sealing ring, M 40, Neoprene
GTIN (EAN)	4008190956066	
Qty.	20 ST	

Polyethylene flat gasket - GWDR PO


In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M40-PO	Version
Order No.	1777970000	GWDR PO (flat gasket - polyethylene), Sealing ring, M 40,
GTIN (EAN)	4032248158232	Polyethylene
Qty.	50 ST	