

VP M50 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	VPMS Ex (ex blanking plug, brass), Blanking plug, straight, M 50, 15 mm, Brass, nickel-plated
Order No.	1210940000
Type	VP M50 EXE MS
GTIN (EAN)	4032248992393
Qty.	5 items
Delivery status	Discontinued
Available until	2024-08-31T00:00:00+02:00
Alternative product	VP-HEX M50-EX W

VP M50 EXE MS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	20 mm	Height (inches)	0.7874 inch
Length	20 mm	Length (inches)	0.7874 inch
Diameter	50 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	14 mm	Net weight	194 g

Temperatures

Operating temperature	-40 °C...100 °C
-----------------------	-----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, Imidazolidine-2-thione 96-45-7
SCIP	4efa9808-c72a-4b94-8dcb-498465ba8c6e

Certificate numbers cable gland

Identification	II 2 GD, Ex d IIC, Ex e II, Ex tD	Certificate no. cable gland (ATEX)	INERIS 09 ATEX 0059X
----------------	-----------------------------------	------------------------------------	----------------------

General information

O-Ring	NBR	Silicone	No
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Pitch of thread	1.5 mm	Halogen	Yes
AF size 1	58 mm	Protection degree	IP54, IP64, IP68
Basic material	Brass, nickel-plated	Diameter of sealing ring	50.00 mm
External thread	M 50	Length of thread	15 mm
Torque for cap nut, max.	16.20 Nm	Torque for connecting adapter, max.	54.00 Nm
Torque for connecting adapter, min.	27.00 Nm	Torque for cap nut, min.	10.80 Nm

Classifications


ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		

VP M50 EXE MS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

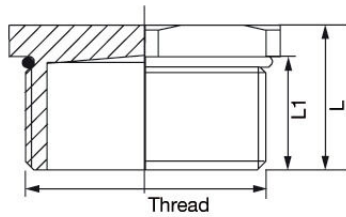

VP M50 EXE MS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Brass lock nuts, nickel-plated**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU M50 MS	Version
Order No.	1737040000	SKMU MS (brass locknut), Locknut, M 50, 5 mm, Brass, nickel-plated
GTIN (EAN)	4008190956516	
Qty.	25 ST	

Neoprene flat gasket - GWDR NP

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M50-NP	Version
Order No.	1736280000	GWDR NP (flat gasket - neoprene), Sealing ring, M 50, Neoprene
GTIN (EAN)	4008190956073	
Qty.	20 ST	

Polyethylene flat gasket - GWDR PO

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M50-PO	Version
Order No.	1777980000	GWDR PO (flat gasket - polyethylene), Sealing ring, M 50,
GTIN (EAN)	4032248158249	Polyethylene
Qty.	50 ST	