

## IE-BHD-V01M-SCA

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



Bayonet plug-in connectors according to IEC  
61076-3-106 ver.1 (EtherNet/IP), metal, empty housing

### General ordering data

Version	Empty enclosure, Flange-mounted housing, Variant 1 to IEC 61076-3-106, IP67
Order No.	<a href="#">1221030000</a>
Type	IE-BHD-V01M-SCA
GTIN (EAN)	4050118003956
Qty.	10 items

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E316369

**Dimensions and weights**

Depth	27 mm	Depth (inches)	1.063 inch
Height	32 mm	Height (inches)	1.2598 inch
Width	32 mm	Width (inches)	1.2598 inch
Net weight	56.4 g		

**Temperatures**

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

**General data**

Colour	Miscellaneous	Housing main material	Zinc diecast
Type of mounting	4 screws, Central nut	Protection degree	IP67
Plugging cycles	750		


**General standards**

Connector standard	IEC 61076-3-106 Var. 1	Certificate no. (cULus)	E316369
--------------------	------------------------	-------------------------	---------

**Classifications**

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		

**Installation cut-out**

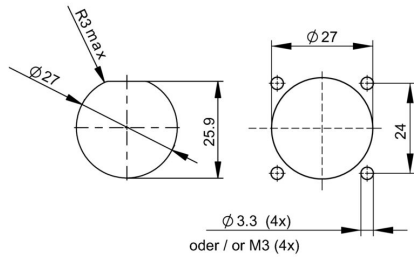

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

**Detailed drawing**



Wall thickness when using the central screw connection