


**FTA-C300-32DO-FUSE-S****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

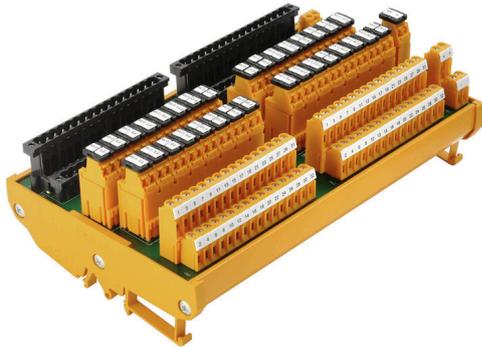

Digital input/output direct FTAs for Honeywell C300 IOTAs.

Passive interfaces (FTA) for connecting the Honeywell C300 digital IOTAs.

- Clearly labelled: Same connector and position on the FTA and on the IOTA.
- The light indicator (LED) indicates the position of the switch.
- Possibility of feeding the IOTA from the FTA (fuse protected).
- Fuse protection per channel (optional).
- Screw or tension clamp connection.

**General ordering data**

Order No.	1246910000
Type	<a href="#">FTA-C300-32DO-FUSE-S</a>
GTIN (EAN)	4050118035124
Qty.	1 items
Delivery status	This article will no longer be available in the future.
Last order date	2026-02-10T00:00:00+01:00

## FTA-C300-32DO-FUSE-S

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E141197

## Dimensions and weights

Depth	95 mm	Depth (inches)	3.7401 inch
Height	133 mm	Height (inches)	5.2362 inch
Width	217 mm	Width (inches)	8.5433 inch
Net weight	701.95 g		

## Temperatures

Storage temperature	-40...60 °C	Operating temperature	-25...50 °C
---------------------	-------------	-----------------------	-------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c, 7cl
REACH SVHC	Lead 7439-92-1
SCIP	2e4a427f-c282-4ebf-8ee2-8af7c9348f4e

## Rated data UL

Rated current IN	1 A	Operating temperature UL, min.	0 °C
Operating temperature UL, max.	25 °C	Rated voltage UN	24 V DC
Rated voltage DC UN (supply)	24 V	Rated current (supply)	5 A
Rated current fuse (supply)	5 A	Rated current fuse (channel)	0.5 A

## General data

LED status display per channel	No	Type of test point	No
Fuse per channel	500 mA	LED status of the supply voltage	yellow
Power supply fuse	5 A		

## Connection data

Connection (field side)	LL2N 5.08 mm	Connection on control side	SLDV-THR 5.08
-------------------------	--------------	----------------------------	---------------

## Ratings data

Operating voltage	24 V DC ± 10%	Max. current per channel	1 A
-------------------	---------------	--------------------------	-----

## Insulation coordination (EN50178)

Rated insulation voltage	<50 V AC	Surge voltage category	III
Pollution severity level	2	Pulse voltage test (1,2/50µs)	0.8 kV
Insulation test voltage AC	0.35 kV		

**FTA-C300-32DO-FUSE-S**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data**

**Connection field**

Clamping range, max.	6 mm <sup>2</sup>	Clamping range, min.	0.13 mm <sup>2</sup>
----------------------	-------------------	----------------------	----------------------

**Supply connection**

Clamping range, min.	0.13 mm <sup>2</sup>	Clamping range, max.	6 mm <sup>2</sup>
----------------------	----------------------	----------------------	-------------------

**Classifications**

ETIM 8.0	EC002780	ETIM 9.0	EC002780
ETIM 10.0	EC002780	ECLASS 14.0	27-14-11-52
ECLASS 15.0	27-14-11-52		

**FTA-C300-32DO-FUSE-S**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

