


## IE-BHS-V14M-RJA-45

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

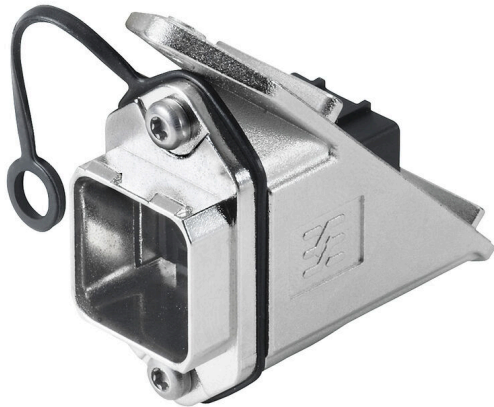

PushPull plug-in connector according to IEC  
61076-3-117 ver.14 (PROFINET), metal, RJ45 empty  
housing

### General ordering data

Version	Empty enclosure, Flange, angled
Order No.	<a href="#">1296710000</a>
Type	IE-BHS-V14M-RJA-45
GTIN (EAN)	4050118094831
Qty.	10 items

## IE-BHS-V14M-RJA-45

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

### Dimensions and weights

Depth	54.9 mm	Depth (inches)	2.1614 inch
Height	52.4 mm	Height (inches)	2.063 inch
Width	24.3 mm	Width (inches)	0.9567 inch
Net weight	81.66 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Type of mounting	2 screws, M3 (not included)	Protection degree	IP67

### General standards

Certificate no. (cULus)	E316369
-------------------------	---------

### Classifications

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		


IE-BHS-V14M-RJA-45

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

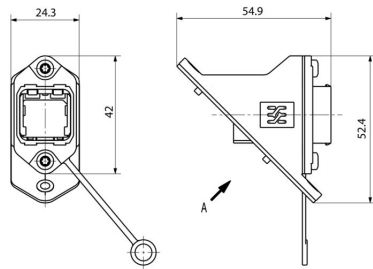

Dimensioned drawing

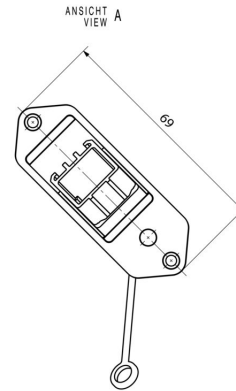

Installation cut-out

