


IE-CD-V14MHYB-Y-MA-K1

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

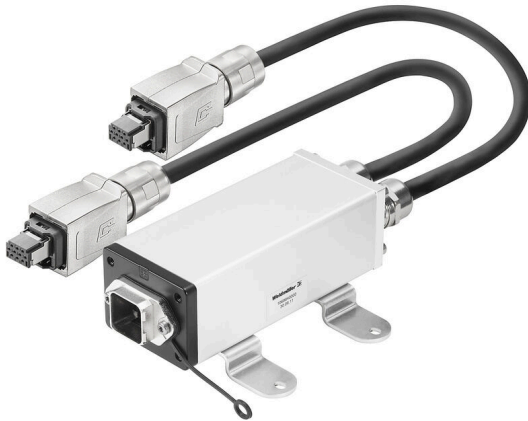

Y-distributor, FreeCon version for push-pull plug connector var. 14 as per IEC 61076-3-117 in metal with hybrid 10-pole insert

General ordering data

Version	Y-distributor, FreeCon, Hybrid, IP65
Order No.	1312230000
Type	IE-CD-V14MHYB-Y-MA-K1
GTIN (EAN)	4050118115000
Qty.	1 items

IE-CD-V14MHYB-Y-MA-K1

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 1050 g

Temperatures

Storage temperature -40 °C...75 °C Operating temperature -40 °C...70 °C
 Installation temperature

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC Lead 7439-92-1
 SCIP 67cf1078-beca-4687-860b-dc475a6ec24a

General data

UL 94 flammability rating V-0 Housing main material Aluminium profile, Cover: die-cast zinc, painted
 Protection degree IP65

General standards

Connector standard IEC 61076-3-117 Var. 14

Technical specifications for hybrid connector

Plugging cycles (hybrid connector)	500	Housing base material (hybrid connector)	Zinc diecast (flange), PA 66
Shielding (hybrid connector)	360° shield contact	Material of seal (hybrid connector)	NBR
Rated voltage (DIN EN 61984) (hybrid connector)	24 V	Contact material (hybrid connector)	Copper alloy
Contact resistance (hybrid connector)	≤ 10 mΩ	Protection degree (hybrid connector)	IP65
Pole count	10	Rated current (hybrid connector)	3 A per contact

Classifications

ETIM 8.0	EC002597	ETIM 9.0	EC002597
ETIM 10.0	EC002597	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

