

**IE-CD-V14MHYB-Y-MA-K1**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com



Y-distributor, FreeCon version for push-pull plug connector var. 14 as per IEC 61076-3-117 in metal with hybrid 10-pole insert

**General ordering data**

Version	Y-distributor, FreeCon, Hybrid, IP65
Order No.	<a href="#">1312230000</a>
Type	IE-CD-V14MHYB-Y-MA-K1
GTIN (EAN)	4050118115000
Qty.	1 items

## IE-CD-V14MHYB-Y-MA-K1

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Net weight	1050 g
------------	--------

### Temperatures

Storage temperature	-40 °C...75 °C	Operating temperature	-40 °C...70 °C
Installation temperature			

### Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

### General data

UL 94 flammability rating	V-0	Housing main material	Aluminium profile, Cover: die-cast zinc, painted
Protection degree	IP65		

### General standards


Connector standard	IEC 61076-3-117 Var. 14
--------------------	-------------------------

### Technical specifications for hybrid connector

Plugging cycles (hybrid connector)	500	Housing base material (hybrid connector)	Zinc diecast (flange), PA 66
Shielding (hybrid connector)	360° shield contact	Material of seal (hybrid connector)	NBR
Rated voltage (DIN EN 61984) (hybrid connector)	24 V	Contact material (hybrid connector)	Copper alloy
Contact resistance (hybrid connector)	≤ 10 mΩ	Protection degree (hybrid connector)	IP65
Pole count	10	Rated current (hybrid connector)	3 A per contact

### Classifications

ETIM 8.0	EC002597	ETIM 9.0	EC002597
ETIM 10.0	EC002597	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

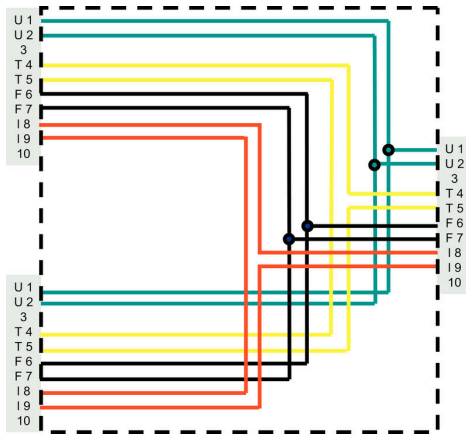

## IE-CD-V14MHYB-Y-MA-K1

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Dust caps




For protecting your devices against dust and dirt.

### General ordering data

Type	IE-BP-V14P	Version	
Order No.	<a href="#">1058310000</a>	Flange-mounted housing, protective cap	
GTIN (EAN)	4032248799404		
Qty.	10 ST		

### Sets - hybrid

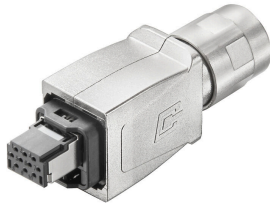

PushPull plug-in connector set according to IEC 61076-3-117 ver.14 (PROFINET), metal incl. hybrid insert

### General ordering data

Type	IE-PS-V14M-HYB-10P	Version	
Order No.	<a href="#">1072910000</a>	Hybrid plug, Cat.5 (ISO/IEC 11801)	
GTIN (EAN)	4032248831128		
Qty.	10 ST		