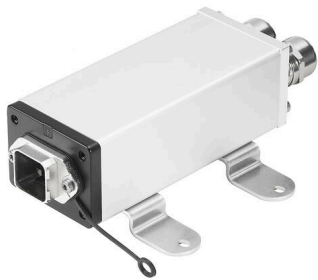


IE-CD-V14MHYB-Y-MA**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Y-distributor, FreeCon version for push-pull plug connector var. 14 as per IEC 61076-3-117 in metal with hybrid 10-pole insert

General ordering data

Version	Y-distributor, FreeCon, Hybrid, IP65
Order No.	1312580000
Type	IE-CD-V14MHYB-Y-MA
GTIN (EAN)	4050118115208
Qty.	1 items

IE-CD-V14MHYB-Y-MA

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 709 g

Temperatures

Storage temperature Operating temperature -40 °C...70 °C
 Installation temperature

Environmental Product Compliance

RoHS Compliance Status Compliant with exemption
 RoHS Exemption (if applicable/known) 6c
 REACH SVHC Lead 7439-92-1
 SCIP 67cf1078-beca-4687-860b-dc475a6ec24a

General data

UL 94 flammability rating V-0 Colour silver
 Housing main material Aluminium profile, Cover: die-cast zinc, painted Type of mounting Screw mounting
 Protection degree IP65

General standards

Connector standard IEC 61076-3-117 Var. 14

Technical specifications for hybrid connector

Plugging cycles (hybrid connector) 500 Housing base material (hybrid connector) Zinc diecast (flange), PA 66
 Shielding (hybrid connector) 360° shield contact Material of seal (hybrid connector) NBR
 Rated voltage (DIN EN 61984) (hybrid connector) 24 V Contact material (hybrid connector) Copper alloy
 Contact resistance (hybrid connector) ≤ 10 mΩ Protection degree (hybrid connector) IP65
 Pole count 10 Rated current (hybrid connector) 3 A per contact

Classifications

ETIM 8.0 EC002597 ETIM 9.0 EC002597
 ETIM 10.0 EC002597 ECLASS 14.0 27-44-03-18
 ECLASS 15.0 27-44-03-18

IE-CD-V14MHYB-Y-MA

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensional drawing

