

## SM 46/46-30 MC SDR


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

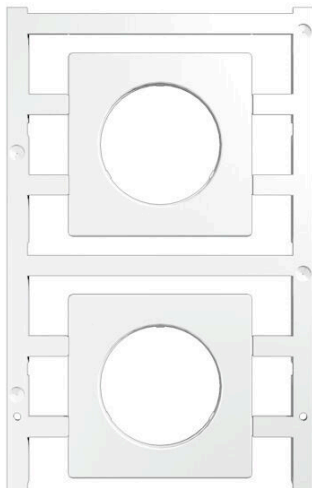

SM is a MultiCard marker for labelling control and signalling devices. The tags are clipped into the carriers or attached by means of the adhesive film already fitted to them. Customised tags can be created with the PrintJet CONNECT or Plotter marking systems.

- Users can quickly produce tags to suit their needs
- No need to stock expensive standard tags
- Highly resistant printing quality when using the PrintJet as a substitute for engraving
- For extreme demands, we recommend the ETO SM protective film
- Holders can be used for the 22-mm or 30-mm-diameter push-buttons from Siemens, ABB, Moeller and Télémécanique

For custom printing: Please send us a file of our labelling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

### General ordering data

Version	SwitchMark, Device markers, 46 x 46 mm, for cam switches, Type S0, Kraus & Naimer, To customer specification
Order No.	<a href="#">1323610000</a>
Type	SM 46/46-30 MC SDR
GTIN (EAN)	4050118126907
Qty.	4 items

**SM 46/46-30 MC SDR**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	1.2 mm	Depth (inches)	0.0472 inch
Height	46 mm	Height (inches)	1.811 inch
Width	46 mm	Width (inches)	1.811 inch
Diameter	30 mm	Net weight	3.57 g

**Temperatures**

Operating temperature range	-40...100 °C
-----------------------------	--------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption	
REACH SVHC	No SVHC above 0.1 wt%	
Product Carbon Footprint	Cradle to gate	0.037 kg CO2 eq.

**General data**

Version	pluggable	
Width	46 mm	
UL 94 flammability rating	V-2	
Operating temperature range, max.	100 °C	
Operating temperature range, min.	-40 °C	
Colour	To customer specification	
Halogen	No	
Basic material	Polyamide 66	
Printed characters	Requires M-Print PRO File	
Number of markers per packaging unit	Form of supply	MultiCard
compatible printer	<a href="#">PRINTJET CONNECT</a> , <a href="#">MCP BASIC 2</a> , <a href="#">MCP PLUS 2</a>	
Number of markers per combination	1 MultiCard = Device markers	
Operating temperature range	-40...100 °C	
Application/manufacturer	for cam switches, Type SO, Kraus & Naimer	

**Device markers**

Diameter	30 mm	Halogen	No
----------	-------	---------	----

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

