


PM 2.7/2.6 MC NE WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

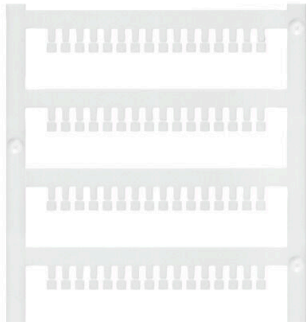

General ordering data

| | |
|-----------------|---|
| Version | OMNIMATE Signal - series PM, Pusher markers, 2.7 x 2.6 mm, Pitch in mm (P): 3.50 Weidmueller, white |
| Order No. | 1323710000 |
| Type | PM 2.7/2.6 MC NE WS |
| GTIN (EAN) | 4050118126778 |
| Qty. | 960 items |
| Delivery status | This article will no longer be available in the future. |
| Available until | 2025-12-31T00:00:00+01:00 |

PM 2.7/2.6 MC NE WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Height | 2.7 mm | Height (inches) | 0.1063 inch |
| Width | 2.6 mm | Width (inches) | 0.1024 inch |
| Net weight | 0.1 g | | |

Temperatures

Operating temperature range -40...100 °C

Environmental Product Compliance

| | | | |
|--------------------------|-----------------------------|------------------|--|
| RoHS Compliance Status | Compliant without exemption | | |
| REACH SVHC | No SVHC above 0.1 wt% | | |
| Product Carbon Footprint | Cradle to gate | 0.001 kg CO2 eq. | |

General data

| | | | |
|---|--|-----------|--|
| Width | 2.6 mm | | |
| UL 94 flammability rating | V-2 | | |
| Operating temperature range, max. | 100 °C | | |
| Operating temperature range, min. | -40 °C | | |
| Colour | white | | |
| Halogen | No | | |
| Basic material | Polyamide 66 | | |
| Printed characters | neutral | | |
| Number of markers per packaging unit | Form of supply | MultiCard | |
| Recommended industries compatible printer | Device manufacturer PRINTJET CONNECT , MCP BASIC 2 , MCP PLUS 2 | | |
| Number of markers per combination | 1 MultiCard = Pusher markers | | |
| Operating temperature range | -40...100 °C | | |
| Application/manufacturer | Weidmueller | | |

Connector markers

Pitch in mm (P) 3.50 mm

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000761 | ETIM 9.0 | EC000761 |
| ETIM 10.0 | EC000761 | ECLASS 14.0 | 27-28-11-01 |
| ECLASS 15.0 | 27-28-11-01 | | |

Drawings



Drawing

