


## AP 80 OR 2000

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

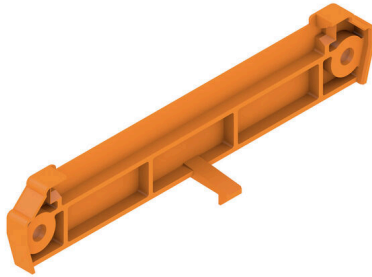

The RS 100 Profi offers you a flexible solution for your mounting needs, as both DIN rail mounting and wall mounting are possible. This versatility facilitates integration into different environments and applications. The housing can be used for the Eurocard PCB standard. The profile can be cut to size so that you can adapt it precisely to your specific requirements. For particularly heavy components, additional locking feet can be used to improve stability and thus increase the safety of your installation.

Another practical feature is the option of using a cover profile to protect large components.

### General ordering data

Version	End plate, RS 80 orange, End plate both sides, Width: 12.3 mm
Order No.	<a href="#">1324260000</a>
Type	AP 80 OR 2000
GTIN (EAN)	4008190181932
Qty.	20 items

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	20 mm	Depth (inches)	0.7874 inch
Height	86.4 mm	Height (inches)	3.4016 inch
Width	12.3 mm	Width (inches)	0.4843 inch
Net weight	2.33 g		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Material data**

UL 94 flammability rating	V-0	Insulating material	PA 66
Insulating material group	I	Surface finish	untreated
Basic material	PA 66	Comparative Tracking Index (CTI)	600 ≤ CTI

**General data**

Colour	orange	Protection degree	IP20 in installed state
Colour chart (similar)	RAL 2000	Encapsulation option	No

**Classifications**

ETIM 8.0	EC001031	ETIM 9.0	EC002779
ETIM 10.0	EC002779	ECLASS 14.0	27-19-06-02
ECLASS 15.0	27-19-06-02		

