

IE-BI-BNC-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



BNC coupling as per IEC 61169-8

General ordering data

Version	Coupling
Order No.	1345020000
Type	IE-BI-BNC-C
GTIN (EAN)	4050118149340
Qty.	1 items

IE-BI-BNC-C

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Net weight	18 g
------------	------

Temperatures

Storage temperature	Operating temperature
Installation temperature	

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

General data

O-Ring	NBR	Housing main material	Brass, nickel-plated
Insulation	PTFE	Wave impedance	50 Ω
Return loss (attenuation)	23 dB at 4 GHz, 27 dB at 1 GHz		

General standards


Connector standard	IEC 61169-8
--------------------	-------------

Classifications

ETIM 8.0	EC001121	ETIM 9.0	EC001121
ETIM 10.0	EC001121	ECLASS 14.0	27-44-03-90
ECLASS 15.0	27-44-03-90		

Drawings

Dimensioned drawing

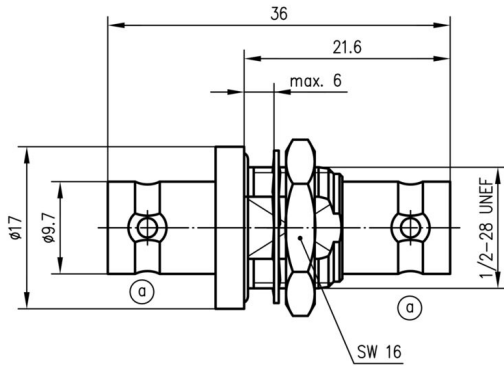

Installation cut-out

