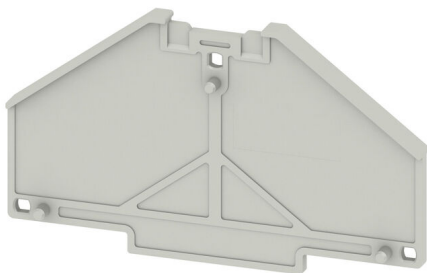


**TW PRV4 SDR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

**General ordering data**

|            |                                                                   |
|------------|-------------------------------------------------------------------|
|            |                                                                   |
| Version    | P-series, Partition plate, grey, 2 mm, Customer-specific printing |
| Order No.  | <a href="#">1389210000</a>                                        |
| Type       | TW PRV4 SDR                                                       |
| GTIN (EAN) | 4050118189568                                                     |
| Qty.       | 10 items                                                          |

## TW PRV4 SDR

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 41.1 mm | Depth (inches)  | 1.6181 inch |
| Height     | 70 mm   | Height (inches) | 2.7559 inch |
| Width      | 2 mm    | Width (inches)  | 0.0787 inch |
| Net weight | 4.57 g  |                 |             |

## Temperatures

|                                  |                |                                  |                |
|----------------------------------|----------------|----------------------------------|----------------|
| Storage temperature              | -25 °C...55 °C | Ambient temperature              | -50 °C...80 °C |
| Continuous operating temp., min. | -50 °C         | Continuous operating temp., max. | 125 °C         |

## Environmental Product Compliance

|                          |                             |                  |  |
|--------------------------|-----------------------------|------------------|--|
| RoHS Compliance Status   | Compliant without exemption |                  |  |
| REACH SVHC               | No SVHC above 0.1 wt%       |                  |  |
| Product Carbon Footprint | Cradle to gate              | 0.036 kg CO2 eq. |  |

## Material data

|                           |               |        |      |
|---------------------------|---------------|--------|------|
| Basic material            | Polycarbonate | Colour | grey |
| UL 94 flammability rating | V-0           |        |      |

## System specifications

|         |                            |
|---------|----------------------------|
| Version | Customer-specific printing |
|---------|----------------------------|

## Additional technical data

|         |     |
|---------|-----|
| Snap-on | Yes |
|---------|-----|

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000886    | ETIM 9.0    | EC000886    |
| ETIM 10.0   | EC000886    | ECLASS 14.0 | 27-25-03-01 |
| ECLASS 15.0 | 27-25-03-01 |             |             |