

ZQV 1.5N/R6.4/10 BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image



General ordering data

Version	TERMSERIES, Cross-connector
Order No.	1390350000
Type	ZQV 1.5N/R6.4/10 BL
GTIN (EAN)	4050118190793
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2021-06-30T00:00:00+02:00
Alternative product	TCC 6.4/10 BL

ZQV 1.5N/R6.4/10 BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	4.9 mm	Depth (inches)	0.1929 inch
Height	13.1 mm	Height (inches)	0.5157 inch
Width	61 mm	Width (inches)	2.4016 inch
Net weight	3.54 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...60 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Rated current (UL)	10 A
--------------------	------

General data

Version	can be cut to length	Colour	blue
---------	----------------------	--------	------

Insulation coordination

Rated voltage	250 V
---------------	-------

Connection data

Pitch in mm (P)	6.40 mm
-----------------	---------

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		


ZQV 1.5N/R6.4/10 BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensional drawing

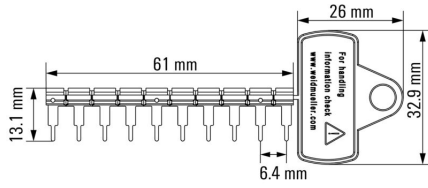

ZQV 1.5N/R6.4/10 BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cutting tools



Cutting tools for conductors up to 8 mm, 12 mm, 14 mm and 22 mm outside diameter. The special blade geometry allows pinch-free cutting of copper and aluminium conductors with minimum physical effort. The cutting tools (KT 8 to KT 22) also come with VDE and GS-tested protective insulation up to 1,000 V in accordance with EN/IEC 60900.

General ordering data

Type	KT 14	Version	
Order No.	1157820000	Cutting tools, Cutting tool for one-hand operation	
GTIN (EAN)	4032248945344		
Qty.	1 ST		

Cutting and notching tools for cross-connections



- for Weidmüller Z-Series cross-connections
- for cross-connections from WQV 2.5 to WQV 35
- for cross-connection window of the terminal WSI 6

General ordering data

Type	KT ZQV	Version	
Order No.	9002170000	Cutting tool for one-hand operation	
GTIN (EAN)	4032248291670		
Qty.	1 ST		
Type	WAW 1 NEUTRAL	Version	
Order No.	9004500000	Miscellaneous tools	
GTIN (EAN)	4008190053925		
Qty.	1 ST		