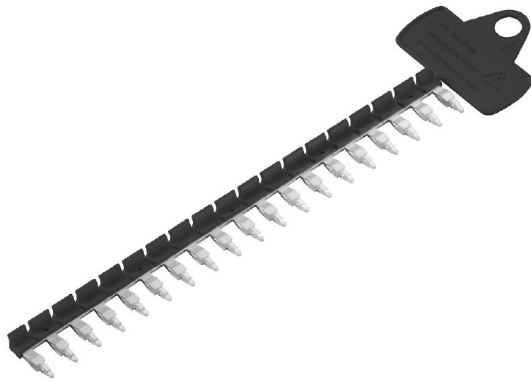


ZQV 1.5N/R6.4/19 SW**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image****General ordering data**

Version	TERMSERIES, Cross-connector
Order No.	1391600000
Type	ZQV 1.5N/R6.4/19 SW
GTIN (EAN)	4050118191806
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2021-06-30T00:00:00+02:00
Alternative product	TCC 6.4/51 BK

ZQV 1.5N/R6.4/19 SW**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Approvals**

ROHS	Conform
------	---------

Dimensions and weights

Depth	4.9 mm	Depth (inches)	0.1929 inch
Height	13.1 mm	Height (inches)	0.5157 inch
Width	119 mm	Width (inches)	4.685 inch
Net weight	4.65 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...60 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Rated current (UL)	10 A
--------------------	------

General data

Version	can be cut to length	Colour	black
---------	----------------------	--------	-------

Insulation coordination

Rated voltage	250 V
---------------	-------

Connection data


Pitch in mm (P)	6.40 mm
-----------------	---------

Classifications

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 9.1	27-37-16-92
ECLASS 10.0	27-37-16-92	ECLASS 11.0	27-37-16-92
ECLASS 12.0	27-37-16-92	ECLASS 13.0	27-37-16-92
ECLASS 14.0	27-37-16-92	ECLASS 15.0	27-37-16-92

Drawings

Dimensional drawing

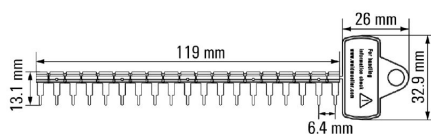

ZQV 1.5N/R6.4/19 SW

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cutting tools



Cutting tools for conductors up to 8 mm, 12 mm, 14 mm and 22 mm outside diameter. The special blade geometry allows pinch-free cutting of copper and aluminium conductors with minimum physical effort. The cutting tools (KT 8 to KT 22) also come with VDE and GS-tested protective insulation up to 1,000 V in accordance with EN/IEC 60900.

General ordering data

Type	KT 14	Version
Order No.	1157820000	Cutting tools, Cutting tool for one-hand operation
GTIN (EAN)	4032248945344	
Qty.	1 ST	

Cutting and notching tools for cross-connections



- for Weidmüller Z-Series cross-connections
- for cross-connections from WQV 2.5 to WQV 35
- for cross-connection window of the terminal WSI 6

General ordering data

Type	KT ZQV	Version
Order No.	9002170000	Cutting tool for one-hand operation
GTIN (EAN)	4032248291670	
Qty.	1 ST	
Type	WAW 1 NEUTRAL	Version
Order No.	9004500000	Miscellaneous tools
GTIN (EAN)	4008190053925	
Qty.	1 ST	