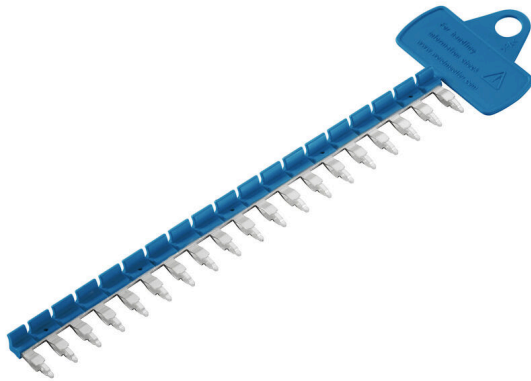


ZQV 1.5N/R6.4/19 BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Product image**General ordering data**

Version	TERMSERIES, Cross-connector
Order No.	1391620000
Type	ZQV 1.5N/R6.4/19 BL
GTIN (EAN)	4050118191813
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2021-06-30T00:00:00+02:00
Alternative product	TCC 6.4/51 BL

ZQV 1.5N/R6.4/19 BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	4.9 mm	Depth (inches)	0.1929 inch
Height	13.1 mm	Height (inches)	0.5157 inch
Width	119 mm	Width (inches)	4.685 inch
Net weight	4.65 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...60 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Rated current (UL)	10 A
--------------------	------

General data

Version	can be cut to length	Colour	blue
---------	----------------------	--------	------

Insulation coordination

Rated voltage	250 V
---------------	-------

Connection data

Pitch in mm (P)	6.40 mm
-----------------	---------

Classifications

ETIM 8.0	EC002586	ETIM 9.0	EC002586
ETIM 10.0	EC002586	ECLASS 14.0	27-37-16-92
ECLASS 15.0	27-37-16-92		


ZQV 1.5N/R6.4/19 BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensional drawing

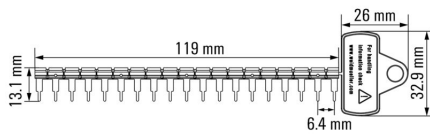

ZQV 1.5N/R6.4/19 BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Cutting tools



Cutting tools for conductors up to 8 mm, 12 mm, 14 mm and 22 mm outside diameter. The special blade geometry allows pinch-free cutting of copper and aluminium conductors with minimum physical effort. The cutting tools (KT 8 to KT 22) also come with VDE and GS-tested protective insulation up to 1,000 V in accordance with EN/IEC 60900.

General ordering data

Type	KT 14	Version	
Order No.	1157820000	Cutting tools, Cutting tool for one-hand operation	
GTIN (EAN)	4032248945344		
Qty.	1 ST		

Cutting and notching tools for cross-connections



- for Weidmüller Z-Series cross-connections
- for cross-connections from WQV 2.5 to WQV 35
- for cross-connection window of the terminal WSI 6

General ordering data

Type	KT ZQV	Version	
Order No.	9002170000	Cutting tool for one-hand operation	
GTIN (EAN)	4032248291670		
Qty.	1 ST		
Type	WAW 1 NEUTRAL	Version	
Order No.	9004500000	Miscellaneous tools	
GTIN (EAN)	4008190053925		
Qty.	1 ST		