


**H35,0/30 DS RT**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Similar to illustration**

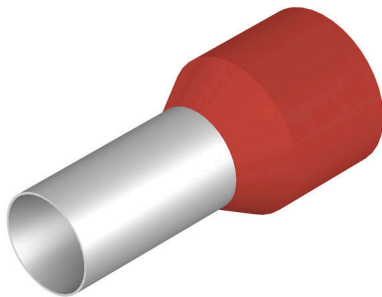

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
 Material: E-Cu, tin galvanised  
 Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Standard, 19 mm, 16 mm, red
Order No.	<a href="#">1418020000</a>
Type	H35,0/30 DS RT
GTIN (EAN)	4050118221466
Qty.	50 items
Packaging	loose

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986

**Dimensions and weights**

Net weight	1.86 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, special size, red	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	8.3 mm	Contact surface length (L2)	16 mm
Collar diameter (D2)	12.7 mm	Plastic collar thickness (S2)	0.4 mm
L1 in mm	30.00 mm	Wire connection cross section AWG, max.	AWG 2
Metal sleeve thickness (S1)	0.2 mm	Stripping length	19 mm
Conductor cross-section	35 mm <sup>2</sup>	Colour code	DIN

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

