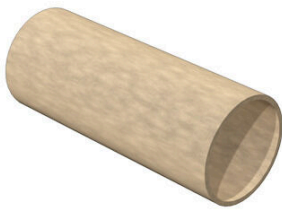


THM MMP RB KE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | |
|------------|-------------------------------|
| Order No. | 1419920000 |
| Type | THM MMP RB KE |
| GTIN (EAN) | 4050118223439 |
| Qty. | 1 items |

THM MMP RB KE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | |
|------------|---------|
| Net weight | 20.24 g |
|------------|---------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Labelling systems

| | |
|---------|--|
| Version | Replacement part for thermotransfer printer, colour ribbon core, inner diameter 1 inch |
|---------|--|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000610 | ETIM 9.0 | EC000610 |
| ETIM 10.0 | EC000610 | ECLASS 14.0 | 24-32-11-90 |
| ECLASS 15.0 | 24-32-11-90 | | |