


## IE-FSMZ2LY0020MLD0LD0-X

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

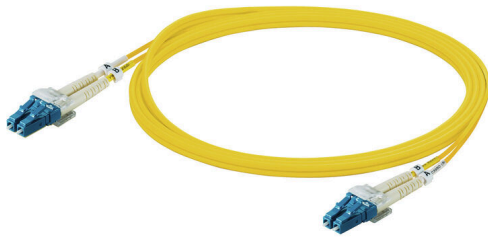

Assembled IE cables, FO

### General ordering data

Version	Pre-assembled patch cable, crossover, LC-Duplex IP 20, LC-Duplex IP 20, 9 µm, LSZH, 20 m
Order No.	<a href="#">1433950200</a>
Type	IE-FSMZ2LY0020MLD0LD0-X
GTIN (EAN)	4050118694239
Qty.	1 items

**IE-FSMZ2LY0020MLD0LD0-X**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Length	20 m	Length (inches)	787.4016 inch
Net weight	146.08 g		

**Temperatures**

Storage temperature	-25 °C...75 °C	Operating temperature	-5 °C...75 °C
Installation temperature	-5 °C...50 °C		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Fibre-optic**

Fibre type Singlemode, OS1

**Cable structure**

Sheath diameter	3*6 mm	Sheathing colour	yellow
Standard designations	I-V(ZN)Y	Material sheath	LSZH
Cable layout	ZIPCORD	Primary coating	245.00 µm
Core diameter	9 µm		

**Plug**

Plug right	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded	Plug left	LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded
------------	--	-----------	--

**Plug, left**

Plug left LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded

**Plug, right**

Plug right LC-Duplex, IP20, male contact, straight, plug, Plastic, unshielded

**Classifications**

ETIM 8.0	EC002607	ETIM 9.0	EC002607
ETIM 10.0	EC002607	ECLASS 14.0	27-06-10-03
ECLASS 15.0	27-06-10-03		

**Drawings**

**Detailed drawing**

