

HDC MHP100 M 25**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

General ordering data

| | |
|------------|---------------------------------------|
| Version | Male, silver, 25 - 25 mm ² |
| Order No. | 1435770000 |
| Type | HDC MHP100 M 25 |
| GTIN (EAN) | 4050118240573 |
| Qty. | 10 items |

HDC MHP100 M 25

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Net weight 14.22 g

Temperatures

Limit temperature -40 °C ... 125 °C

Environmental Product Compliance

RoHS Compliance Status Compliant with exemption

RoHS Exemption (if applicable/known) 6c

REACH SVHC Lead 7439-92-1

SCIP 6eabd5ae-2d6b-409e-8bdf-87c27ee10e40

General data

| | | | |
|-------------------------------|--------------------|------------------------------------|-------------------------|
| Contact diameter, male Ø | 6.55 mm | Stripping length, rated connection | 19 mm |
| Type of connection | Crimp connection | Version insert | MHP |
| Conductor cross-section, max. | 25 mm ² | Conductor cross-section, min. | 25 mm ² |
| Surface finish | silver | Plugging cycles | ≥ 500 |
| Type | Male | Basic material | Copper alloy |
| Production methods | turned | Cross-section for connected wire | 25 - 25 mm ² |

Classifications


| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000796 | ETIM 9.0 | EC000796 |
| ETIM 10.0 | EC000796 | ECLASS 14.0 | 27-44-02-04 |
| ECLASS 15.0 | 27-44-02-04 | | |

HDC MHP100 M 25

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

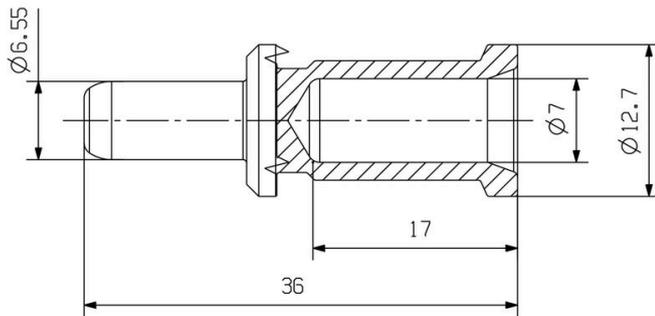

HDC MHP100 M 25

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

| | | |
|------------|----------------------------|--|
| Type | EPG 45 | Version |
| Order No. | 1500830000 | Pressing tool, 6mm ² , 150mm ² , Hexagonal crimp, WM crimp, Indent |
| GTIN (EAN) | 4050118309317 | crimp, Trapezoidal crimp, Oval crimping |
| Qty. | 1 ST | |

... for compression cable lugs (acc. to DIN 46235)



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

| | | |
|------------|----------------------------|-------------------------------------|
| Type | ES EPG 45 HEX 25/50 | Version |
| Order No. | 1500970000 | 50mm ² , Hexagonal crimp |
| GTIN (EAN) | 4050118309195 | |
| Qty. | 1 ST | |