


## H10,0/28S SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration

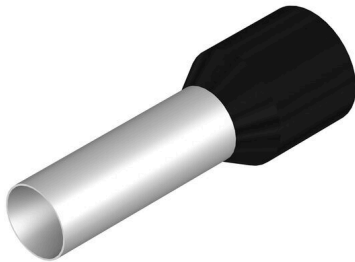

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

### General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, black
Order No.	<a href="#">1462590000</a>
Type	H10,0/28S SW
GTIN (EAN)	4050118268775
Qty.	100 items

**H10,0/28S SW**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Net weight 0.62 g

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Technical data**

Description of article	Wire end ferrule with plastic collar, special size, black	Version	Standard
------------------------	---	---------	----------

**Wire-end ferrules**

Contact surface diameter (D1)	4.6 mm	Contact surface length (L2)	18 mm
Collar diameter (D2)	7.4 mm	Plastic collar thickness (S2)	0.3 mm
L1 in mm	27.50 mm	Wire connection cross section AWG, max.	AWG 8
Metal sleeve thickness (S1)	0.2 mm	Stripping length	21 mm
Conductor cross-section	10 mm <sup>2</sup>		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

