

## SAI-ADAPT-M8/M12 3P

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



M8/M12 and M12/M8 adapters serve for quick implementation of the plug size.

### General ordering data

Version	Y connector, M8 / M12
Order No.	<a href="#">1473460000</a>
Type	SAI-ADAPT-M8/M12 3P
GTIN (EAN)	4050118279696
Qty.	1 items

## SAI-ADAPT-M8/M12 3P

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E307231

## Dimensions and weights

Net weight 12.32 g

## Environmental Product Compliance

RoHS Compliance Status Compliant

REACH SVHC Lead 7439-92-1

SCIP 1c533b66-fcff-4da5-b89f-fd55fbf5cb55

## Connection data

Single outlet 1 - plug-in connector M8 pin Single outlet 2 - plug-in connector M12 socket

Tightening torque M12: 0.8 Nm, M8: 0.5 Nm

## Technical data customisable plug-in connectors

Number of poles 3 Coding M12 = A-coded, M8 = none

Nominal voltage 24 V Protection degree IP67

Pollution severity 3

## Standards

Connector standard IEC 61076-2-101, IEC 61076-2-104

## General data

Number of poles 3 Coding M12 = A-coded, M8 = none

Connection thread M8 / M12 Nominal voltage 24 V

Protection degree IP67 Pollution severity 3

Connection 1 M8/M12 Connection 2 Screw

Conductor O.D. -

## Classifications

ETIM 8.0 EC002925 ETIM 9.0 EC002925

ETIM 10.0 EC002925 ECLASS 14.0 27-44-01-06

ECLASS 15.0 27-44-01-06


**SAI-ADAPT-M8/M12 3P**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Dimensioned drawing**

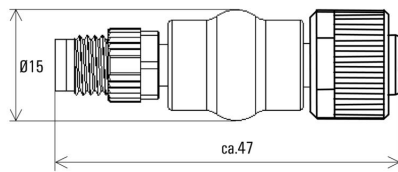

**Wiring diagram**

