


## H0,75/14D GR SP

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration

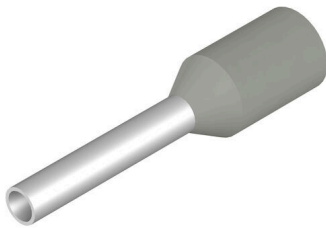

- supplied loose in polybag
- in multipack bag (5 x 100 pcs.)
- strip of wire end ferrules (50 pcs.)
- strip of wire end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
Order No.	<a href="#">1476310000</a>
Type	H0,75/14D GR SP
GTIN (EAN)	4050118283303
Qty.	100 items

## H0,75/14D GR SP

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986

### Dimensions and weights

Net weight	0.09 g
------------	--------

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Technical data

Description of article	Wire end ferrule with plastic collar, grey	Version	Standard
------------------------	--	---------	----------

### Wire-end ferrules

Contact surface diameter (D1)	1.2 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	2.8 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 18
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	0.75 mm <sup>2</sup>	Colour code	DIN

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

