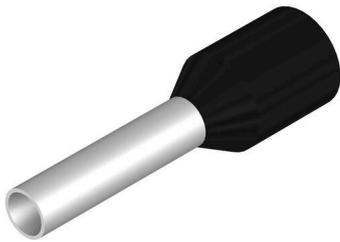


**H1,5/14D SW SP**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Similar to illustration**

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.14 – 150 mm<sup>2</sup> (AWG 26-300 MCM)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, black
Order No.	<a href="#">1476330000</a>
Type	H1,5/14D SW SP
GTIN (EAN)	4050118283075
Qty.	100 items

## H1,5/14D SW SP

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986

### Dimensions and weights

Net weight	0.12 g
------------	--------

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### Technical data

Description of article	Wire end ferrule with plastic collar, black	Version	Standard
------------------------	---	---------	----------

### Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar diameter (D2)	3.5 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	14.00 mm	Wire connection cross section AWG, max.	AWG 16
Metal sleeve thickness (S1)	0.15 mm	Stripping length	10 mm
Conductor cross-section	1.5 mm <sup>2</sup>	Colour code	DIN

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

