


ES APG 80 AEH 120**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

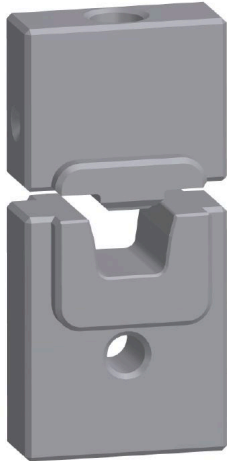

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

Version	120mm ² , Trapezoidal crimp
Order No.	1502090000
Type	ES APG 80 AEH 120
GTIN (EAN)	4050118310146
Qty.	1 items

ES APG 80 AEH 120

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	386 g
------------	-------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Crimp inserts

Crimping width	24 mm	Crimp cross-section copper	120
Crimping width in mm	24		

Description of contact

Conductor cross-section, max. AWG	4/0	Conductor cross-section, min. AWG	4/0
Crimping range, max.	120 mm ²		

tool data crimping

Crimping type/profile	Trapezoidal crimp
Cable lug cross section	nominal 120 mm ²

Classifications

ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		