


ES APG 80 WM 150**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

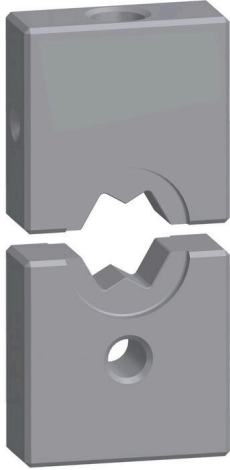

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
 - electronic control and monitoring of the crimping process
 - Saving of all crimping cycles and error messages to internal memory
 - Reading of all cycles and error messages via USB

General ordering data

| | |
|------------|-------------------------------|
| Version | 150mm ² , WM crimp |
| Order No. | 1502550000 |
| Type | ES APG 80 WM 150 |
| GTIN (EAN) | 4050118310825 |
| Qty. | 1 items |

ES APG 80 WM 150

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 304.5 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Crimp inserts

Crimping width 5 mm Crimp cross-section copper 150
 Crimping width in mm 5

Description of contact

Conductor cross-section, max. AWG 5/0 Conductor cross-section, min. AWG 5/0
 Crimping range, max. 150 mm²

tool data crimping

Crimping type/profile WM crimp
 Cable lug cross section nominal 150 mm²

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001282 | ETIM 9.0 | EC001282 |
| ETIM 10.0 | EC001282 | ECLASS 14.0 | 21-04-90-90 |
| ECLASS 15.0 | 21-04-90-90 | | |