


ES APG 80 HEX 240**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

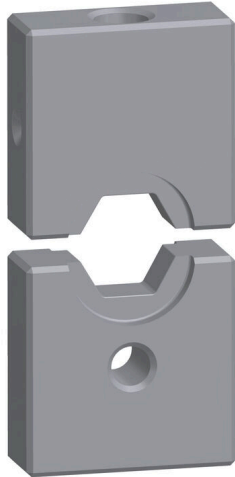

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
 - electronic control and monitoring of the crimping process
 - Saving of all crimping cycles and error messages to internal memory
 - Reading of all cycles and error messages via USB

General ordering data

Version	240mm ² , Hexagonal crimp
Order No.	1502740000
Type	ES APG 80 HEX 240
GTIN (EAN)	4050118310481
Qty.	1 items

ES APG 80 HEX 240

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	285.8 g
------------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Crimp inserts

Identification number	28	Crimping width	5 mm
Crimp cross-section aluminium	185	Crimp cross-section copper	240
Crimping width in mm	5		

Description of contact

Conductor cross-section, max. AWG	450	Conductor cross-section, min. AWG	450
Crimping range, max.	240 mm ²		

tool data crimping

Crimping type/profile	Hexagonal crimp
Cable lug cross section	nominal 240 mm ²

Classifications

ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		