

**HSS-HF 9.5-19.1 EL W30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com



The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

**General ordering data**

|            |   |
|------------|---|
| Version    | Conductor and cable markers, 9.5 - 19.1 mm, white |
| Order No.  | <a href="#">1513320000</a>                        |
| Type       | HSS-HF 9.5-19.1 EL W30M                           |
| GTIN (EAN) | 4050118320954                                     |
| Qty.       | 1 items   |

**HSS-HF 9.5-19.1 EL W30M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 1.5 mm   | Depth (inches)  | 0.0591 inch |
| Width      | 30.9 mm  | Width (inches)  | 1.2165 inch |
| Length     | 30000 mm | Length (inches) | 1181.1 inch |
| Net weight | 993.52 g |                 |             |

**Temperatures**

Operating temperature range -55...105 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

|                                   |              |                                   |  |
|-----------------------------------|--------------|-----------------------------------|--|
| Type of printing                  | neutral      | Width                             | 30.9 mm  |
| Operating temperature range, max. | 105 °C       | Operating temperature range, min. | -55 °C   |
| Colour                            | white        | Halogen                           | No   |
| Length                            | 30000 mm     | Basic material                    | Polyolefine  |
| Printed characters                | without      | compatible printer                | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> |
| Operating temperature range       | -55...105 °C | Number per roll                   | 1  |

**Conductor and cable markers**

|                                   |                         |                               |                    |
|-----------------------------------|-------------------------|-------------------------------|--------------------|
| Halogen                           | No                      | Conductor cross-section, max. | 70 mm <sup>2</sup> |
| Conductor cross-section, min.     | 16 mm <sup>2</sup>      | Conductor O.D., max.          | 19.1 mm            |
| Conductor O.D., min.              | 9.5 mm                  | Rate of shrinkage             | 2:1                |
| Recommended shrinking temperature | 90 °C                   | Conductor O.D.                | 9.5 - 19.1 mm      |
| Cross-section for connected wire  | 16 - 70 mm <sup>2</sup> |                               |                    |

**Important note**

Product information External roll holder 1302920000 necessary

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |

**HSS-HF 9.5-19.1 EL W30M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



## HSS-HF 9.5-19.1 EL W30M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

# Accessories

## Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |            |
|------------|----------------------------|------------|
| Type       | RIBBON HSS HF EL 40/300... | Version    |
| Order No.  | <a href="#">1426210000</a> | Ink ribbon |
| GTIN (EAN) | 4050118228823              |            |
| Qty.       | 1 ST                       |            |

## THM MULTIMARK

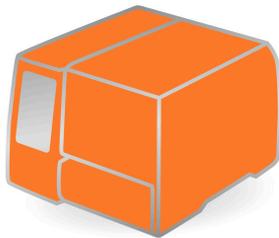

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |         |
|------------|----------------------------|---------|
| Type       | THM MMP EXT.RH             | Version |
| Order No.  | <a href="#">1302920000</a> |         |
| GTIN (EAN) | 4050118102307              |         |
| Qty.       | 1 ST                       |         |
| Type       | MULTIMARK ROLLER 115       | Version |
| Order No.  | <a href="#">1357420000</a> |         |
| GTIN (EAN) | 4050118160314              |         |
| Qty.       | 1 ST                       |         |
| Type       | MULTIMARK ROLLER 30        | Version |
| Order No.  | <a href="#">1357430000</a> |         |
| GTIN (EAN) | 4050118160253              |         |
| Qty.       | 1 ST                       |         |


## HSS-HF 9.5-19.1 EL W30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### THM MULTIMARK PLUS

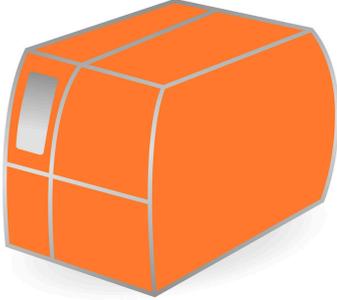

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK PLUS ROLLER 1... | Version |  |
| Order No.  | <a href="#">2672590000</a> |         |  |
| GTIN (EAN) | 4050118708097              |         |  |
| Qty.       | 1 ST                       |         |  |