

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Version	Pressing tool, Crimping tool for wire-end ferrules, 0.14mm ² , 6mm ² , Trapezoidal crimp
Order No.	1527230000
Type	PZ 6 ROTO L ZERT
GTIN (EAN)	4050118332698
Qty.	1 items

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.8661 inch
Height	80 mm	Height (inches)	3.1496 inch
Width	200 mm	Width (inches)	7.874 inch
Net weight	432 g		

Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1
SCIP	2159813b-98fd-4068-b62a-bc89a046c012

Technical data

Description of article	(1)Crimping tool	Version	Mechanical, without interchangeable inserts
------------------------	------------------	---------	---

Description of contact

Type of contact	Wire-end ferrules with/without plastic collars	Conductor cross-section, max. AWG	AWG 10
Conductor cross-section, min. AWG	AWG 26	Crimping range, max.	6 mm ²
Crimping range, min.	0.14 mm ²		

tool data crimping

Drive	mechanical	Wire end ferrules cross-section, max.	6 mm ²
Crimping type/profile	Trapezoidal crimp		

Classifications

ETIM 8.0	EC000168	ETIM 9.0	EC000168
ETIM 10.0	EC000168	ECLASS 14.0	21-04-38-11
ECLASS 15.0	21-04-38-11		



Example of use



Example of use



PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Accessories / replacement parts



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Type	ERTE ES PZ 6 ROTO L	Version	
Order No.	2561810000		
GTIN (EAN)	4050118570199		
Qty.	1 ST		

Replacement parts



After stripping the insulation, a suitable contact or wire end ferrule can be crimped onto the end of the cable. Crimping forms a secure connection between conductor and contact and has largely replaced soldering. Crimping denotes the creation of a homogeneous, permanent connection between conductor and connecting element. The connection can be made only with high-quality precision tools. The result is a secure and reliable connection both in mechanical and electrical terms. Weidmüller offers a wide range of mechanical crimping tools. Integral ratchets with release mechanisms guarantee optimum crimping. Crimped connections made with Weidmüller tools comply with international standards and regulations.

General ordering data

Type	ERTE GRIFFE PZ	Version	
Order No.	9202810000	Pressing tool, Replacement part	
GTIN (EAN)	4032248512577		
Qty.	1 ST		

Accessories / replacement parts



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	ERSATZTEILSET CLIP PZ 6...	Version
Order No.	9054820000	
GTIN (EAN)	4032248 109289	
Qty.	1 ST	

Conductor nom. cross-section 0.14mm²



- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,14/10 GR SV	Version
Order No.	9005180000	Wire-end ferrule, Standard, 8 mm, 6 mm, grey
GTIN (EAN)	4008190859909	
Qty.	500 ST	
Type	H0,14/10T BR SV	Version
Order No.	9028250000	Wire-end ferrule, Standard, 8 mm, 6 mm, brown
GTIN (EAN)	4008190902018	
Qty.	500 ST	
Type	H0,14/12 GR SV	Version
Order No.	9028240000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190902001	
Qty.	500 ST	

Multi-bag



- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,25/10 HBL SV	Version
Order No.	9026050000	Wire-end ferrule, Standard, 8 mm, 6 mm, Light Blue
GTIN (EAN)	4008190138288	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H0,25/10T GE	Version	
Order No.	9021010000	Wire-end ferrule, Standard, 8 mm, 6 mm, yellow	
GTIN (EAN)	4008190109103		
Qty.	500 ST		

Multi-bag



- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,25/10T GE SV	Version	
Order No.	9021210000	Wire-end ferrule, Standard, 8 mm, 6 mm, yellow	
GTIN (EAN)	4008190045555		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H0,25/10 HBL	Version	
Order No.	9025740000	Wire-end ferrule, Standard, 8 mm, 6 mm, Light Blue	
GTIN (EAN)	4008190092054		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H0,25/12 HBL	Version	
Order No.	9025760000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue	
GTIN (EAN)	4008190010027		
Qty.	500 ST		

Multi-bag



- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,25/12 HBL SV	Version	
Order No.	9025780000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue	
GTIN (EAN)	4008190053239		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H0,25/12T GE	Version	
Order No.	9021020000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow	
GTIN (EAN)	4008190184230		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Multi-bag



- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Type	H0,25/12T GE SV	Version	
Order No.	9021220000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow	
GTIN (EAN)	4008190153786		
Qty.	500 ST		

Type	H0,34/10 TK SV	Version	
Order No.	9026030000	Wire-end ferrule, Standard, 8 mm, 6 mm, Turquoise	
GTIN (EAN)	4008190177171		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H0,34/12 TK	Version	
Order No.	9025770000	Wire-end ferrule, Standard, 10 mm, 8 mm, Turquoise	
GTIN (EAN)	4008190067960		
Qty.	500 ST		

Multi-bag



- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H0.34/12 TK SV	Version	
Order No.	9025790000	Wire-end ferrule, Standard, 10 mm, 8 mm, Turquoise	
GTIN (EAN)	4008190121174		
Qty.	500 ST		

in multipack bag



- In multi-pack bag
- Weidmüller colour code

General ordering data

Type	H1,5/17,5X SW SV	Version	
Order No.	9006590000	Wire-end ferrule, Standard, 13 mm, 8 mm, black	
GTIN (EAN)	4008190332259		
Qty.	100 ST		

Type	H1,5/19,5X SW SV	Version	
Order No.	9006630000	Wire-end ferrule, Standard, 15 mm, 10 mm, black	
GTIN (EAN)	4008190332266		
Qty.	100 ST		

supplied loose in polybag



- In multi-pack bag
- Weidmüller colour code

General ordering data

Type	H1,5/24 XS SW	Version	
Order No.	9202870000	Wire-end ferrule, Standard, 18 mm, 14.5 mm, black	
GTIN (EAN)	4032248517947		
Qty.	100 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

in multipack bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H2,5/17,5X BL SV	Version	
Order No.	9006670000	Wire-end ferrule, Standard, 14 mm, 8 mm, blue	
GTIN (EAN)	4008190332273		
Qty.	100 ST		

Type	H2,5/21,5X BL SV	Version	
Order No.	9006710000	Wire-end ferrule, Standard, 17 mm, 12 mm, blue	
GTIN (EAN)	4008190332280		
Qty.	100 ST		

supplied loose in polybag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H2,5/24 XS BL	Version	
Order No.	9202880000	Wire-end ferrule, Standard, 18 mm, 14.5 mm, blue	
GTIN (EAN)	4032248517954		
Qty.	100 ST		

in multipack bag



- Polypropylene conical cable entry
 - Heat-resistant up to 105°C
- for conductors from 1.5 to 16 mm² (AWG 16-6)
 tin-plated copper
 dimensional tolerances to DIN 46228 part 4

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H4,0/19,5X GR SV	Version
Order No.	9006750000	Wire-end ferrule, Standard, 14 mm, 10 mm, grey
GTIN (EAN)	4008190332297	
Qty.	100 ST	
Type	H6,0/23X GE SV	Version
Order No.	9006790000	Wire-end ferrule, Standard, 17 mm, 12 mm, yellow
GTIN (EAN)	4008190332303	
Qty.	100 ST	

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code

General ordering data

Type	H0,34/10 TK	Version
Order No.	9025750000	Wire-end ferrule, Standard, 8 mm, 6 mm, Turquoise
GTIN (EAN)	4008190105365	
Qty.	500 ST	

Strip of wire end ferrules on reel



- strip of wire end ferrules on reel (5,000 pcs.)
- Weidmüller colour code

General ordering data

Type	H0,34/12 TK BD GSP	Version
Order No.	9004390000	Wire-end ferrule, Standard, 10 mm, 8 mm, Turquoise
GTIN (EAN)	4008190881016	
Qty.	5000 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/12 OR SV	Version
Order No.	9028260000	Wire-end ferrule, Standard, 8 mm, 6 mm, orange
GTIN (EAN)	4008190902025	
Qty.	500 ST	
Type	H0,5/14 OR SV	Version
Order No.	9026060000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
GTIN (EAN)	4008190122201	
Qty.	500 ST	
Type	H0,5/14D W SV	Version
Order No.	9019400000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190066024	
Qty.	500 ST	
Type	H0,5/16 OR SV	Version
Order No.	9028270000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
GTIN (EAN)	4008190902049	
Qty.	500 ST	

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/12 OR	Version
Order No.	0409500000	Wire-end ferrule, Standard, 8 mm, 6 mm, orange
GTIN (EAN)	4008190090456	
Qty.	500 ST	
Type	H0,5/12D W	Version
Order No.	9019000000	Wire-end ferrule, Standard, 8 mm, 6 mm, white
GTIN (EAN)	4008190085728	
Qty.	500 ST	

PZ 6 ROTO L ZERT


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H0,5/14 OR	Version
Order No.	0690700000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
GTIN (EAN)	4008190015770	
Qty.	500 ST	
Type	H0,5/14D W	Version
Order No.	9019010000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190120931	
Qty.	500 ST	
Type	H0,5/16 OR	Version
Order No.	9025870000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
GTIN (EAN)	4008190025045	
Qty.	500 ST	
Type	H0,5/16D W	Version
Order No.	9019020000	Wire-end ferrule, Standard, 12 mm, 10 mm, white
GTIN (EAN)	4008190047108	
Qty.	500 ST	
Type	H0,5/18 OR	Version
Order No.	1076980000	Wire-end ferrule, Standard, 14 mm, 12 mm, orange
GTIN (EAN)	4032248834631	
Qty.	500 ST	
Type	H0,5/18D W	Version
Order No.	1076990000	Wire-end ferrule, Standard, 14 mm, 12 mm, white
GTIN (EAN)	4032248834624	
Qty.	500 ST	

Strip of wire end ferrules on reel

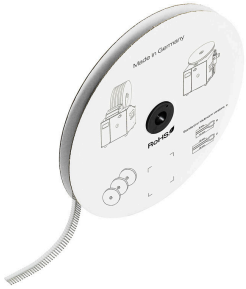

- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/14 OR BD GSP	Version
Order No.	9005810000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
GTIN (EAN)	4008190275877	
Qty.	5000 ST	
Type	H0,5/14D W BD GSP	Version
Order No.	9005860000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190275921	
Qty.	5000 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Strip of wire end ferrules



- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/14 OR BD	Version	
Order No.	9004270000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange	
GTIN (EAN)	4008190091774		
Qty.	500 ST		
Type	H0,5/14D W BD	Version	
Order No.	9004280000	Wire-end ferrule, Standard, 10 mm, 8 mm, white	
GTIN (EAN)	4008190162627		
Qty.	500 ST		
Type	H0,5/14T W BD	Version	
Order No.	9021930000	Wire-end ferrule, Standard, 10 mm, 8 mm, white	
GTIN (EAN)	4008190262402		
Qty.	500 ST		

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/12 W SV	Version	
Order No.	9028280000	Wire-end ferrule, Standard, 8 mm, 6 mm, white	
GTIN (EAN)	4008190902216		
Qty.	500 ST		
Type	H0,75/14 W SV	Version	
Order No.	9026070000	Wire-end ferrule, Standard, 10 mm, 8 mm, white	
GTIN (EAN)	4008190187163		
Qty.	500 ST		
Type	H0,75/14D GR SV	Version	
Order No.	9019410000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey	
GTIN (EAN)	4008190164096		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H0,75/14T HBL SV	Version
Order No.	9021230000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
GTIN (EAN)	4008190153106	
Qty.	500 ST	
Type	H0,75/16 W SV	Version
Order No.	9028290000	Wire-end ferrule, Standard, 12 mm, 10 mm, white
GTIN (EAN)	4008190902056	
Qty.	500 ST	
Type	H0,75/18 W SV	Version
Order No.	9028300000	Wire-end ferrule, Standard, 14 mm, 12 mm, white
GTIN (EAN)	4008190902063	
Qty.	500 ST	

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/12 W	Version
Order No.	0409600000	Wire-end ferrule, Standard, 8 mm, 6 mm, white
GTIN (EAN)	4008190079826	
Qty.	500 ST	
Type	H0,75/12D GR	Version
Order No.	9019030000	Wire-end ferrule, Standard, 8 mm, 6 mm, grey
GTIN (EAN)	4008190127787	
Qty.	500 ST	
Type	H0,75/12T HBL	Version
Order No.	9021030000	Wire-end ferrule, Standard, 8 mm, 6 mm, Light Blue
GTIN (EAN)	4008190152901	
Qty.	500 ST	
Type	H0,75/14 W	Version
Order No.	0462900000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190033248	
Qty.	500 ST	
Type	H0,75/14D GR	Version
Order No.	9019040000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190099077	
Qty.	500 ST	
Type	H0,75/16 W	Version
Order No.	9025860000	Wire-end ferrule, Standard, 12 mm, 10 mm, white
GTIN (EAN)	4008190141967	
Qty.	500 ST	

PZ 6 ROTO L ZERT


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H0,75/16D GR	Version
Order No.	9019050000	Wire-end ferrule, Standard, 12 mm, 10 mm, grey
GTIN (EAN)	4008190033002	
Qty.	500 ST	
Type	H0,75/16T HBL	Version
Order No.	9021050000	Wire-end ferrule, Standard, 12 mm, 10 mm, Light Blue
GTIN (EAN)	4008190096175	
Qty.	500 ST	
Type	H0,75/18 W	Version
Order No.	9025910000	Wire-end ferrule, Standard, 14 mm, 12 mm, white
GTIN (EAN)	4008190063702	
Qty.	500 ST	
Type	H0,75/18D GR	Version
Order No.	9019060000	Wire-end ferrule, Standard, 14 mm, 12 mm, grey
GTIN (EAN)	4008190049560	
Qty.	500 ST	
Type	H0,75/18T HBL	Version
Order No.	9021060000	Wire-end ferrule, Standard, 14 mm, 12 mm, Light Blue
GTIN (EAN)	4008190071158	
Qty.	500 ST	
Type	H0,75/14T HBL	Version
Order No.	9021040000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
GTIN (EAN)	4008190083168	
Qty.	500 ST	

Strip of wire end ferrules on reel

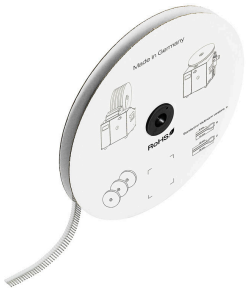

- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/14 W BD GSP	Version
Order No.	9005820000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190275884	
Qty.	5000 ST	
Type	H0,75/14D GR BD GSP	Version
Order No.	9005870000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190275938	
Qty.	5000 ST	
Type	H0,75/14T BL BD GSP	Version
Order No.	9005900000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
GTIN (EAN)	4008190275969	
Qty.	5000 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Strip of wire end ferrules



- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/14 W BD	Version
Order No.	9004290000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190006778	
Qty.	500 ST	
Type	H0,75/14D GR BD	Version
Order No.	9004300000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190154837	
Qty.	500 ST	
Type	H0,75/14T HBL BD	Version
Order No.	9004310000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
GTIN (EAN)	4008190179298	
Qty.	500 ST	

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H1,0/12 GE SV	Version
Order No.	9028310000	Wire-end ferrule, Standard, 8 mm, 6 mm, yellow
GTIN (EAN)	4008190902070	
Qty.	500 ST	
Type	H1,0/14 GE SV	Version
Order No.	9026080000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190026158	
Qty.	500 ST	
Type	H1,0/14D R SV	Version
Order No.	9019420000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190189099	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,0/16 GE SV	Version
Order No.	9028320000	Wire-end ferrule, Standard, 12 mm, 10 mm, yellow
GTIN (EAN)	4008190902087	
Qty.	500 ST	
Type	H1,0/18 GE SV	Version
Order No.	9028340000	Wire-end ferrule, Standard, 15 mm, 12 mm, yellow
GTIN (EAN)	4008190902100	
Qty.	500 ST	

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/12 GE	Version
Order No.	0409700000	Wire-end ferrule, Standard, 8 mm, 6 mm, yellow
GTIN (EAN)	4008190152222	
Qty.	500 ST	
Type	H1,0/12D R	Version
Order No.	9019070000	Wire-end ferrule, Standard, 8 mm, 6 mm, red
GTIN (EAN)	4008190029074	
Qty.	500 ST	
Type	H1,0/14 GE	Version
Order No.	0463000000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190024697	
Qty.	500 ST	
Type	H1,0/14D R	Version
Order No.	9019080000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190090623	
Qty.	500 ST	
Type	H1,0/16 GE	Version
Order No.	9025950000	Wire-end ferrule, Standard, 12 mm, 10 mm, yellow
GTIN (EAN)	4008190037291	
Qty.	500 ST	
Type	H1,0/16D R	Version
Order No.	9019100000	Wire-end ferrule, Standard, 12 mm, 10 mm, red
GTIN (EAN)	4008190159986	
Qty.	500 ST	
Type	H1,0/18 GE	Version
Order No.	9025930000	Wire-end ferrule, Standard, 15 mm, 12 mm, yellow
GTIN (EAN)	4008190101497	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,0/18D R	Version
Order No.	9019110000	Wire-end ferrule, Standard, 15 mm, 12 mm, red
GTIN (EAN)	4008190174828	
Qty.	500 ST	

Strip of wire end ferrules on reel



- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H1,0/14 GE BD GSP	Version
Order No.	9005830000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190275891	
Qty.	5000 ST	
Type	H1,0/14D R BD GSP	Version
Order No.	9005880000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190275945	
Qty.	5000 ST	

Strip of wire end ferrules



- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H1,0/14 GE BD	Version
Order No.	9004320000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190167523	
Qty.	500 ST	
Type	H1,0/14D R BD	Version
Order No.	9004330000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190047498	
Qty.	500 ST	
Type	H1,0/14T R BD	Version
Order No.	9021950000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190262747	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,5/14 R SV	Version	
Order No.	9026090000	Wire-end ferrule, Standard, 10 mm, 8 mm, red	
GTIN (EAN)	4008190137168		
Qty.	500 ST		
Type	H1,5/14D SW SV	Version	
Order No.	9019430000	Wire-end ferrule, Standard, 10 mm, 8 mm, black	
GTIN (EAN)	4008190107420		
Qty.	500 ST		
Type	H1,5/16 R SV	Version	
Order No.	9028350000	Wire-end ferrule, Standard, 12 mm, 10 mm, red	
GTIN (EAN)	4008190902117		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,5/14 R	Version	
Order No.	0463100000	Wire-end ferrule, Standard, 10 mm, 8 mm, red	
GTIN (EAN)	4008190065089		
Qty.	500 ST		
Type	H1,5/14D SW	Version	
Order No.	9019120000	Wire-end ferrule, Standard, 10 mm, 8 mm, black	
GTIN (EAN)	4008190153793		
Qty.	500 ST		
Type	H1,5/16 R	Version	
Order No.	0635100000	Wire-end ferrule, Standard, 12 mm, 10 mm, red	
GTIN (EAN)	4008190141745		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,5/16D SW	Version
Order No.	9019130000	Wire-end ferrule, Standard, 12 mm, 10 mm, black
GTIN (EAN)	4008190023331	
Qty.	500 ST	
Type	H1,5/18D SW	Version
Order No.	9019140000	Wire-end ferrule, Standard, 15 mm, 12 mm, black
GTIN (EAN)	4008190046026	
Qty.	500 ST	
Type	H1,5/24 R	Version
Order No.	0565600000	Wire-end ferrule, Standard, 20 mm, 18 mm, red
GTIN (EAN)	4008190187071	
Qty.	500 ST	
Type	H1,5/24D SW	Version
Order No.	9019150000	Wire-end ferrule, Standard, 20 mm, 18 mm, black
GTIN (EAN)	4008190151676	
Qty.	500 ST	

Strip of wire end ferrules on reel



- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H1,5/14 R BD GSP	Version
Order No.	9005840000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190275907	
Qty.	5000 ST	
Type	H1,5/14D SW BD GSP	Version
Order No.	9005890000	Wire-end ferrule, Standard, 10 mm, 8 mm, black
GTIN (EAN)	4008190275952	
Qty.	5000 ST	
Type	H1,5/14S GN BD GSP	Version
Order No.	9028370000	Wire-end ferrule, Standard, 10 mm, 8 mm, green
GTIN (EAN)	4032248318537	
Qty.	5000 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Strip of wire end ferrules



- Linked of wire-end ferrule strips (50 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,5/14 R BD	Version	
Order No.	9004340000	Wire-end ferrule, Standard, 10 mm, 8 mm, red	
GTIN (EAN)	4008190080723		
Qty.	500 ST		
Type	H1,5/14D SW BD	Version	
Order No.	9004350000	Wire-end ferrule, Standard, 10 mm, 8 mm, black	
GTIN (EAN)	4008190005474		
Qty.	500 ST		
Type	H1,5/14T SW BD	Version	
Order No.	9021960000	Wire-end ferrule, Standard, 10 mm, 8 mm, black	
GTIN (EAN)	4008190262389		
Qty.	500 ST		

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H2,5/14S BL SV	Version	
Order No.	9046230000	Wire-end ferrule, Standard, 10 mm, 8 mm, blue	
GTIN (EAN)	4032248298631		
Qty.	500 ST		
Type	H2,5/15 BL SV	Version	
Order No.	9026100000	Wire-end ferrule, Standard, 10 mm, 8 mm, blue	
GTIN (EAN)	4008190141141		
Qty.	500 ST		
Type	H2,5/15T GR SV	Version	
Order No.	9021240000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey	
GTIN (EAN)	4008190115302		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

packed loose in polythene bag



- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Type	H2,5/15D BL	Version
Order No.	9019160000	Wire-end ferrule, Standard, 10 mm, 8 mm, blue
GTIN (EAN)	4008190028732	
Qty.	500 ST	
Type	H2,5/15T GR	Version
Order No.	9021070000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190128944	
Qty.	500 ST	
Type	H2,5/19D BL	Version
Order No.	9019170000	Wire-end ferrule, Standard, 14 mm, 12 mm, blue
GTIN (EAN)	4008190178024	
Qty.	500 ST	
Type	H2,5/19T GR	Version
Order No.	9021080000	Wire-end ferrule, Standard, 14 mm, 12 mm, grey
GTIN (EAN)	4008190149345	
Qty.	500 ST	
Type	H2,5/25D BL	Version
Order No.	9019180000	Wire-end ferrule, Standard, 20 mm, 18 mm, blue
GTIN (EAN)	4008190101145	
Qty.	500 ST	
Type	H2,5/25T GR	Version
Order No.	9021090000	Wire-end ferrule, Standard, 20 mm, 18 mm, grey
GTIN (EAN)	4008190060916	
Qty.	500 ST	

Strip of wire end ferrules on reel



- Linked wire-end ferrules on reel (5,000 pcs.)
- DIN colour code
- other colour code

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H2,5/14D BL BD GSP	Version
Order No.	9005850000	Wire-end ferrule, Standard, 10 mm, 8 mm, blue
GTIN (EAN)	4008190275914	
Qty.	3000 ST	
Type	H2,5/14T GR BD GSP	Version
Order No.	9005910000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190275976	
Qty.	3000 ST	

Strip of wire end ferrules



- Linked of wire-end ferrule strips (50 pcs.)
- DIN colour code
- other colour code

General ordering data

Type	H2,5/14D BL BD	Version
Order No.	9004360000	Wire-end ferrule, Standard, 12 mm, 8 mm, blue
GTIN (EAN)	4008190083397	
Qty.	500 ST	
Type	H2,5/14T GR BD	Version
Order No.	9004370000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4008190052508	
Qty.	500 ST	

Multi-bag



- In multi-pack bag
- Weidmüller colour code
- Other colour code

General ordering data

Type	H4,0/18 GR SV	Version
Order No.	9026010000	Wire-end ferrule, Standard, 12 mm, 10 mm, grey
GTIN (EAN)	4008190117382	
Qty.	250 ST	
Type	H4,0/18T OR SV	Version
Order No.	9021250000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
GTIN (EAN)	4008190159313	
Qty.	250 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

packed loose in polythene bag



- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Type	H4,0/18D GR	Version
Order No.	9019190000	Wire-end ferrule, Standard, 12 mm, 10 mm, grey
GTIN (EAN)	4008190141349	
Qty.	500 ST	
Type	H4,0/18T OR	Version
Order No.	9021100000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
GTIN (EAN)	4008190061708	
Qty.	500 ST	
Type	H4,0/20D GR	Version
Order No.	9019200000	Wire-end ferrule, Standard, 14 mm, 12 mm, grey
GTIN (EAN)	4008190126575	
Qty.	500 ST	
Type	H4,0/20T OR	Version
Order No.	9021110000	Wire-end ferrule, Standard, 14 mm, 12 mm, orange
GTIN (EAN)	4008190035754	
Qty.	500 ST	
Type	H4,0/26D GR	Version
Order No.	9019210000	Wire-end ferrule, Standard, 20 mm, 18 mm, grey
GTIN (EAN)	4008190002336	
Qty.	100 ST	
Type	H4,0/26T OR	Version
Order No.	9021120000	Wire-end ferrule, Standard, 20 mm, 18 mm, orange
GTIN (EAN)	4008190092825	
Qty.	100 ST	

Conductor nom. cross-section 6.0mm²



6 mm²

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H6,0/20T GN	Version
Order No.	9021130000	Wire-end ferrule, Standard, 14 mm, 12 mm, green
GTIN (EAN)	4008190111731	
Qty.	100 ST	
Type	H6,0/20 SW	Version
Order No.	0533500000	Wire-end ferrule, Standard, 14 mm, 12 mm, black
GTIN (EAN)	4008190183905	
Qty.	100 ST	
Type	H6,0/20D GE	Version
Order No.	9019220000	Wire-end ferrule, Standard, 14 mm, 12 mm, yellow
GTIN (EAN)	4008190151607	
Qty.	100 ST	
Type	H6,0/26 SW	Version
Order No.	0565700000	Wire-end ferrule, Standard, 20 mm, 18 mm, black
GTIN (EAN)	4008190026837	
Qty.	100 ST	
Type	H6,0/26D GE	Version
Order No.	9019230000	Wire-end ferrule, Standard, 20 mm, 18 mm, yellow
GTIN (EAN)	4008190072117	
Qty.	100 ST	
Type	H6,0/26T GN	Version
Order No.	9021140000	Wire-end ferrule, Standard, 20 mm, 18 mm, green
GTIN (EAN)	4008190022501	
Qty.	100 ST	

Multi-bag



- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
 Material: E-Cu, tin galvanised
 Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Type	H0,75/14S W SV	Version
Order No.	9025700000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190144104	
Qty.	500 ST	
Type	H1,0/14S GE SV	Version
Order No.	9025710000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190031442	
Qty.	500 ST	
Type	H1,5/14S R SV	Version
Order No.	9025720000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190072681	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

supplied loose in polybag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,5/16S OR	Version
Order No.	9202900000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
GTIN (EAN)	4032248519026	
Qty.	500 ST	
Type	H4,0/20DS GR	Version
Order No.	9203630000	Wire-end ferrule, Standard, 15 mm, 12 mm, grey
GTIN (EAN)	4032248565078	
Qty.	500 ST	
Type	H0,34/11 S TK	Version
Order No.	9204090000	Wire-end ferrule, Standard, 6 mm, 6 mm, Turquoise
GTIN (EAN)	4032248593026	
Qty.	500 ST	
Type	H0,5/14S OR	Version
Order No.	9004560000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
GTIN (EAN)	4008190286132	
Qty.	500 ST	
Type	H0,5/14S W	Version
Order No.	9004590000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190862060	
Qty.	500 ST	
Type	H0,5/16 DS W	Version
Order No.	9202910000	Wire-end ferrule, Standard, 12 mm, 10 mm, white
GTIN (EAN)	4032248519019	
Qty.	500 ST	
Type	H0,75/14DS GR	Version
Order No.	9028580000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4032248159475	
Qty.	500 ST	
Type	H0,75/14S W	Version
Order No.	9025960000	Wire-end ferrule, Standard, 10 mm, 8 mm, white
GTIN (EAN)	4008190009878	
Qty.	500 ST	
Type	H0,75/14TS HBL	Version
Order No.	9018550000	Wire-end ferrule, Standard, 10 mm, 8 mm, Light Blue
GTIN (EAN)	4008190207991	
Qty.	500 ST	
Type	H0,75/15S W	Version
Order No.	9204240000	Wire-end ferrule, Standard, 10 mm, 9 mm, Light Blue, white
GTIN (EAN)	4032248621545	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,0/14S GE	Version
Order No.	9025970000	Wire-end ferrule, Standard, 10 mm, 8 mm, yellow
GTIN (EAN)	4008190063733	
Qty.	500 ST	
Type	H1,0/14S R	Version
Order No.	9018560000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190207984	
Qty.	500 ST	
Type	H1,5/12S R	Version
Order No.	9025690000	Wire-end ferrule, Standard, 8 mm, 6 mm, red
GTIN (EAN)	4008190059439	
Qty.	500 ST	
Type	H1,5/14S R	Version
Order No.	9025980000	Wire-end ferrule, Standard, 10 mm, 8 mm, red
GTIN (EAN)	4008190080730	
Qty.	500 ST	
Type	H1,5/14DS SW	Version
Order No.	9025240000	Wire-end ferrule, Standard, 10 mm, 8 mm, black
GTIN (EAN)	4008190085599	
Qty.	500 ST	
Type	H2,5/12DS BL	Version
Order No.	9028490000	Wire-end ferrule, Standard, 8 mm, 6 mm, blue
GTIN (EAN)	4032248049028	
Qty.	500 ST	
Type	H2,5/12TS GR	Version
Order No.	9036200000	Wire-end ferrule, Standard, 8 mm, 6 mm, grey
GTIN (EAN)	4032248067992	
Qty.	500 ST	
Type	H2,5/14DS BL	Version
Order No.	1333100000	Wire-end ferrule, Standard, 10 mm, 8 mm, blue
GTIN (EAN)	4008190160364	
Qty.	500 ST	
Type	H2,5/14TS GR	Version
Order No.	9426770000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4032248160693	
Qty.	500 ST	
Type	H2,5/16 TS GR	Version
Order No.	9036210000	Wire-end ferrule, Standard, 12 mm, 10 mm, grey
GTIN (EAN)	4032248068005	
Qty.	500 ST	
Type	H2,5/16DS BL	Version
Order No.	9036220000	Wire-end ferrule, Standard, 13 mm, 10 mm, blue
GTIN (EAN)	4032248068012	
Qty.	500 ST	
Type	H4,0/14DS GR	Version
Order No.	9028520000	Wire-end ferrule, Standard, 10 mm, 8 mm, grey
GTIN (EAN)	4032248049035	
Qty.	500 ST	
Type	H4,0/15TS OR	Version
Order No.	9036230000	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
GTIN (EAN)	4032248068029	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Nominal conductor cross-section 0.25 mm² - 6.0 mm²

For conductors from 0.25 to 6,0 mm² (AWG 24 - 10)
 tin-plated copper
 dimensional tolerances to DIN 46228 part 1
 • supplied loose in polybag

General ordering data

Type	H0,25/5	Version
Order No.	9018910000	Wire-end ferrule, Standard, 5 mm, 5 mm, No
GTIN (EAN)	4008190068134	
Qty.	1000 ST	
Type	H0,5/10	Version
Order No.	9004050000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190153052	
Qty.	1000 ST	
Type	H0,5/6	Version
Order No.	0282600000	Wire-end ferrule, Standard, 6 mm, 6 mm, No
GTIN (EAN)	4008190184025	
Qty.	1000 ST	
Type	H0,75/10	Version
Order No.	0542500000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190037482	
Qty.	1000 ST	
Type	H0,75/6	Version
Order No.	0282700000	Wire-end ferrule, Standard, 6 mm, 6 mm, No
GTIN (EAN)	4008190019013	
Qty.	1000 ST	
Type	H1,0/10	Version
Order No.	0282800000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190006662	
Qty.	1000 ST	
Type	H1,0/6	Version
Order No.	0372600000	Wire-end ferrule, Standard, 6 mm, 6 mm, No
GTIN (EAN)	4008190180263	
Qty.	1000 ST	
Type	H1,5/10	Version
Order No.	0186500000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190039592	
Qty.	1000 ST	
Type	H1,5/12	Version
Order No.	9004060000	Wire-end ferrule, Standard, 12 mm, 12 mm, No
GTIN (EAN)	4008190147938	
Qty.	1000 ST	
Type	H1,5/18	Version
Order No.	9004070000	Wire-end ferrule, Standard, 18 mm, 18 mm, No
GTIN (EAN)	4008190105761	
Qty.	1000 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,5/7	Version
Order No.	0372700000	Wire-end ferrule, Standard, 7 mm, 7 mm, No
GTIN (EAN)	4008190064525	
Qty.	1000 ST	
Type	H2,5/10	Version
Order No.	9004080000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190145446	
Qty.	1000 ST	
Type	H2,5/12	Version
Order No.	0186100000	Wire-end ferrule, Standard, 12 mm, 12 mm, No
GTIN (EAN)	4008190172954	
Qty.	1000 ST	
Type	H2,5/18	Version
Order No.	9004090000	Wire-end ferrule, Standard, 18 mm, 18 mm, No
GTIN (EAN)	4008190147921	
Qty.	1000 ST	
Type	H2,5/7	Version
Order No.	0373000000	Wire-end ferrule, Standard, 7 mm, 7 mm, No
GTIN (EAN)	4008190173463	
Qty.	1000 ST	
Type	H4,0/12	Version
Order No.	0244100000	Wire-end ferrule, Standard, 12 mm, 12 mm, No
GTIN (EAN)	4008190179830	
Qty.	1000 ST	
Type	H4,0/15	Version
Order No.	9004100000	Wire-end ferrule, Standard, 15 mm, 15 mm, No
GTIN (EAN)	4008190119003	
Qty.	500 ST	
Type	H4,0/18	Version
Order No.	9004110000	Wire-end ferrule, Standard, 18 mm, 18 mm, No
GTIN (EAN)	4008190148348	
Qty.	500 ST	
Type	H4,0/9	Version
Order No.	0373100000	Wire-end ferrule, Standard, 9 mm, 9 mm, No
GTIN (EAN)	4008190164669	
Qty.	500 ST	
Type	H6,0/10	Version
Order No.	9004120000	Wire-end ferrule, Standard, 10 mm, 10 mm, No
GTIN (EAN)	4008190104795	
Qty.	500 ST	
Type	H6,0/12	Version
Order No.	0191900000	Wire-end ferrule, Standard, 12 mm, 12 mm, No
GTIN (EAN)	4008190026851	
Qty.	500 ST	
Type	H6,0/15	Version
Order No.	0124700000	Wire-end ferrule, Standard, 15 mm, 15 mm, No
GTIN (EAN)	4008190003807	
Qty.	500 ST	
Type	H6,0/18	Version
Order No.	9004130000	Wire-end ferrule, Standard, 18 mm, 18 mm, No
GTIN (EAN)	4008190143626	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Assortment of wire end ferrules with plastic collar



Box filled with wire end ferrules with plastic collar:

- in Weidmüller colour code
- DIN colour code

General ordering data

Type	H-BOX 0,14-0,75QMM	Version
Order No.	9025410000	Assortment of wire end ferrules, Box, Colour code: Weidmüller
GTIN (EAN)	4008190341602	
Qty.	1 ST	
Type	H-BOX 0,5-2,5QMM	Version
Order No.	9025900000	Assortment of wire end ferrules, Box, Colour code: Weidmüller
GTIN (EAN)	4008190109202	
Qty.	1 ST	
Type	H-BOX 0,5-2,5QMM DIN	Version
Order No.	9025430000	Assortment of wire end ferrules, Box, Colour code: DIN
GTIN (EAN)	4008190337162	
Qty.	1 ST	
Type	H-BOX 4,0-16,0QMM	Version
Order No.	9025920000	Assortment of wire end ferrules, Box, Colour code: Weidmüller
GTIN (EAN)	4008190101442	
Qty.	1 ST	
Type	H-BOX 4,0-16,0QMM DIN	Version
Order No.	9025400000	Assortment of wire end ferrules, Box, Colour code: DIN
GTIN (EAN)	4008190341596	
Qty.	1 ST	

Assortment of twin wire end ferrules



Box filled with twin wire end ferrules with plastic collar:

- in Weidmüller colour code

General ordering data

Type	ZH-BOX 0,5-2,5QMM	Version
Order No.	9025390000	Assortment of wire end ferrules, Box, Colour code: Weidmueller
GTIN (EAN)	4008190341015	
Qty.	1 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Multi-bag



- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/14 ZH OR SV	Version
Order No.	9004440000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, orange
GTIN (EAN)	4008190198473	
Qty.	500 ST	

Type	H0,5/14D ZH W SV	Version
Order No.	9004780000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, white
GTIN (EAN)	4008190188481	
Qty.	500 ST	

packed loose in polythene bag



- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H0,5/14 ZH OR	Version
Order No.	9037200000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, orange
GTIN (EAN)	4008190492397	
Qty.	500 ST	

Type	H0,5/14D ZH W	Version
Order No.	9037380000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, white
GTIN (EAN)	4008190492861	
Qty.	500 ST	

Type	H0,5/16 ZH OR	Version
Order No.	9037210000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, orange
GTIN (EAN)	4008190492687	
Qty.	500 ST	

Type	H0,5/16D ZH W	Version
Order No.	9037390000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, white
GTIN (EAN)	4008190492878	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H0,5/18 ZH OR	Version
Order No.	9037220000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange
GTIN (EAN)	4008190492694	
Qty.	500 ST	
Type	H0,5/18D ZH W	Version
Order No.	9037400000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, white
GTIN (EAN)	4008190492892	
Qty.	500 ST	

Multi-bag



- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/14 ZH W SV	Version
Order No.	9018510000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, white
GTIN (EAN)	4008190019914	
Qty.	500 ST	
Type	H0,75/14D ZH GR SV	Version
Order No.	9018520000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, grey
GTIN (EAN)	4008190097998	
Qty.	500 ST	
Type	H0,75/15T ZH BL SV	Version
Order No.	9018570000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, Light Blue
GTIN (EAN)	4008190272630	
Qty.	500 ST	
Type	H0,75/16 ZH W SV	Version
Order No.	9004900000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, white
GTIN (EAN)	4008190482671	
Qty.	500 ST	
Type	H0,75/16D ZH GR SV	Version
Order No.	9004770000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
GTIN (EAN)	4008190038816	
Qty.	500 ST	
Type	H0,75/16T ZH HBL SV	Version
Order No.	9005140000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, Light Blue
GTIN (EAN)	4008190482725	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

packed loose in polythene bag



For the following conductors: 2 No. 0.75 mm² (2 No. AWG 18)

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/14 ZH W	Version
Order No.	9037230000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, white
GTIN (EAN)	4008190853976	
Qty.	500 ST	
Type	H0,75/14D ZH GR	Version
Order No.	9037410000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, grey
GTIN (EAN)	4008190492984	
Qty.	500 ST	
Type	H0,75/14T ZH HBL	Version
Order No.	9037610000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, Light Blue
GTIN (EAN)	4008190493233	
Qty.	500 ST	
Type	H0,75/16 ZH W	Version
Order No.	9037240000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, white
GTIN (EAN)	4008190492717	
Qty.	500 ST	
Type	H0,75/16D ZH GR	Version
Order No.	9037420000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
GTIN (EAN)	4008190492991	
Qty.	500 ST	
Type	H0,75/16T ZH HBL	Version
Order No.	9037620000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, Light Blue
GTIN (EAN)	4008190493264	
Qty.	500 ST	

supplied loose in polybag



- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
 Material: E-Cu, tin galvanised
 Dimensional tolerance acc. to DIN 46228 sect. 4

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H0,75/19DS ZH GR	Version
Order No.	9202830000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
GTIN (EAN)	4032248515776	
Qty.	500 ST	
Type	H0,75/19S ZH W	Version
Order No.	9202820000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, white
GTIN (EAN)	4032248515769	
Qty.	500 ST	
Type	H0,75/19TS ZH HBL	Version
Order No.	9202840000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, Light Blue
GTIN (EAN)	4032248515783	
Qty.	500 ST	

packed loose in polythene bag



For the following conductors: 2 No. 0.75 mm² (2 No. AWG 18)

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H0,75/24 ZH W	Version
Order No.	9037250000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, white
GTIN (EAN)	4008190492724	
Qty.	500 ST	
Type	H0,75/24D ZH GR	Version
Order No.	9037430000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, grey
GTIN (EAN)	4008190493004	
Qty.	500 ST	
Type	H0,75/24T ZH HBL	Version
Order No.	9037630000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, Light Blue
GTIN (EAN)	4008190493271	
Qty.	500 ST	

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H1,0/15 ZH GE SV	Version
Order No.	9018530000	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow
GTIN (EAN)	4008190066925	
Qty.	500 ST	
Type	H1,0/15D ZH R SV	Version
Order No.	9018540000	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, red
GTIN (EAN)	4008190188832	
Qty.	500 ST	
Type	H1,0/15S ZH GE SV	Version
Order No.	9018650000	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow
GTIN (EAN)	4032248011407	
Qty.	500 ST	
Type	H1,0/19 ZH GE SV	Version
Order No.	9004910000	Wire-end ferrule, Twin wire-end ferrule, 16 mm, 12 mm, yellow
GTIN (EAN)	4008190482688	
Qty.	500 ST	
Type	H1,0/19D ZH R SV	Version
Order No.	9004760000	Wire-end ferrule, Twin wire-end ferrule, 16 mm, 12 mm, red
GTIN (EAN)	4008190160951	
Qty.	500 ST	

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/15 ZH GE	Version
Order No.	9037260000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, yellow
GTIN (EAN)	4008190492731	
Qty.	500 ST	
Type	H1,0/15D ZH R	Version
Order No.	9037440000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, red
GTIN (EAN)	4008190493011	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

supplied loose in polybag



- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
 Material: E-Cu, tin galvanised
 Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Type	H1,0/15S ZH GE	Version	
Order No.	9018690000	Wire-end ferrule, Twin wire-end ferrule, 12 mm, 8 mm, yellow	
GTIN (EAN)	4032248017720		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/19 ZH GE	Version	
Order No.	9037270000	Wire-end ferrule, Twin wire-end ferrule, 16 mm, 12 mm, yellow	
GTIN (EAN)	4008190492748		
Qty.	500 ST		
Type	H1,0/19D ZH R	Version	
Order No.	9037450000	Wire-end ferrule, Twin wire-end ferrule, 16 mm, 12 mm, red	
GTIN (EAN)	4008190493028		
Qty.	500 ST		

supplied loose in polybag



- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
 Material: E-Cu, tin galvanised
 Dimensional tolerance acc. to DIN 46228 sect. 4

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H1,0/22DS R ZH	Version	
Order No.	9036330000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 14 mm, red	
GTIN (EAN)	4032248338566		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,0/25 ZH GE	Version	
Order No.	9037280000	Wire-end ferrule, Twin wire-end ferrule, 22 mm, 18 mm, yellow	
GTIN (EAN)	4008190492755		
Qty.	500 ST		

Type	H1,0/25D ZH R	Version	
Order No.	9037460000	Wire-end ferrule, Twin wire-end ferrule, 22 mm, 18 mm, red	
GTIN (EAN)	4008190493035		
Qty.	500 ST		

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,5/16 ZH R SV	Version	
Order No.	9004410000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, red	
GTIN (EAN)	4008190009397		
Qty.	500 ST		

Type	H1,5/16D ZH SW SV	Version	
Order No.	9004420000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, black	
GTIN (EAN)	4008190167455		
Qty.	500 ST		

Type	H1,5/20 ZH R SV	Version	
Order No.	9004920000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, red	
GTIN (EAN)	4008190482695		
Qty.	500 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H1,5/20D SW ZH SV	Version	
Order No.	9004750000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, black	
GTIN (EAN)	4008190055431		
Qty.	500 ST		

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Type	H1,5/16 ZH R	Version	
Order No.	9037290000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, red	
GTIN (EAN)	4008190492762		
Qty.	500 ST		
Type	H1,5/16D ZH SW	Version	
Order No.	9037470000	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, black	
GTIN (EAN)	4008190493042		
Qty.	500 ST		
Type	H1,5/20 ZH R	Version	
Order No.	9037300000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, red	
GTIN (EAN)	4008190492779		
Qty.	500 ST		
Type	H1,5/20D ZH SW	Version	
Order No.	9037480000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, black	
GTIN (EAN)	4008190493059		
Qty.	500 ST		
Type	H1,5/26 ZH R	Version	
Order No.	9037310000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, red	
GTIN (EAN)	4008190492786		
Qty.	100 ST		
Type	H1,5/26D ZH SW	Version	
Order No.	9037490000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, black	
GTIN (EAN)	4008190493066		
Qty.	100 ST		

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

General ordering data

Type	H2,5/19D ZH BL SV	Version
Order No.	9004430000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, blue
GTIN (EAN)	4008190099367	
Qty.	250 ST	
Type	H2,5/19T ZH GR SV	Version
Order No.	9018580000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
GTIN (EAN)	4008190272647	
Qty.	250 ST	
Type	H2,5/21 ZH GR SV	Version
Order No.	9005150000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
GTIN (EAN)	4008190482732	
Qty.	250 ST	
Type	H2,5/21D ZH BL SV	Version
Order No.	9004740000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, blue
GTIN (EAN)	4008190031923	
Qty.	250 ST	

packed loose in polythene bag



- supplied loose in poly-bag
- DIN colour code
- other colour code

General ordering data

Type	H2,5/19D ZH BL	Version
Order No.	9037500000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, blue
GTIN (EAN)	4008190493073	
Qty.	500 ST	
Type	H2,5/19T ZH GR	Version
Order No.	9037640000	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, grey
GTIN (EAN)	4008190493325	
Qty.	500 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	H2,5/21D ZH BL	Version
Order No.	9037510000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, blue
GTIN (EAN)	4008190493080	
Qty.	100 ST	
Type	H2,5/21T ZH GR	Version
Order No.	9037650000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
GTIN (EAN)	4008190493356	
Qty.	100 ST	
Type	H2,5/27D ZH BL	Version
Order No.	9037520000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, blue
GTIN (EAN)	4008190493097	
Qty.	100 ST	
Type	H2,5/27T ZH GR	Version
Order No.	9037660000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, grey
GTIN (EAN)	4008190493387	
Qty.	100 ST	

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

General ordering data

Type	H4,0/22T ZH OR SV	Version
Order No.	9018590000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange
GTIN (EAN)	4008190272654	
Qty.	100 ST	
Type	H4,0/22D ZH GR SV	Version
Order No.	9004730000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
GTIN (EAN)	4008190161811	
Qty.	100 ST	

packed loose in polythene bag



- supplied loose in poly-bag
- DIN colour code
- other colour code

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	H4,0/22D ZH GR	Version
Order No.	9037530000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, grey
GTIN (EAN)	4008190493103	
Qty.	100 ST	
Type	H4,0/22T ZH OR	Version
Order No.	9037670000	Wire-end ferrule, Twin wire-end ferrule, 15 mm, 12 mm, orange
GTIN (EAN)	4008190493431	
Qty.	100 ST	
Type	H4,0/28D ZH GR	Version
Order No.	9037540000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, grey
GTIN (EAN)	4008190493110	
Qty.	100 ST	
Type	H4,0/28T ZH OR	Version
Order No.	9037680000	Wire-end ferrule, Twin wire-end ferrule, 21 mm, 18 mm, orange
GTIN (EAN)	4008190493479	
Qty.	100 ST	

Multi-bag



- in multi-pack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/23 ZH SW SV	Version
Order No.	9004930000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, black
GTIN (EAN)	4008190482701	
Qty.	100 ST	
Type	H6,0/23D ZH GE SV	Version
Order No.	9004720000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, yellow
GTIN (EAN)	4008190962210	
Qty.	100 ST	
Type	H6,0/23T ZH GN SV	Version
Order No.	9005160000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, green
GTIN (EAN)	4008190482749	
Qty.	100 ST	

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

packed loose in polythene bag



- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/23 ZH SW	Version
Order No.	9037320000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, black
GTIN (EAN)	4008190492793	
Qty.	100 ST	
Type	H6,0/23D ZH GE	Version
Order No.	9037550000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, yellow
GTIN (EAN)	4008190493127	
Qty.	100 ST	
Type	H6,0/23T ZH GN	Version
Order No.	9037690000	Wire-end ferrule, Twin wire-end ferrule, 20 mm, 12 mm, green
GTIN (EAN)	4008190493486	
Qty.	100 ST	
Type	H6,0/29 ZH SW	Version
Order No.	9037330000	Wire-end ferrule, Twin wire-end ferrule, 24 mm, 18 mm, black
GTIN (EAN)	4008190492809	
Qty.	100 ST	
Type	H6,0/29D ZH GE	Version
Order No.	9037560000	Wire-end ferrule, Twin wire-end ferrule, 24 mm, 18 mm, yellow
GTIN (EAN)	4008190493134	
Qty.	100 ST	
Type	H6,0/29T ZH GN	Version
Order No.	9037700000	Wire-end ferrule, Twin wire-end ferrule, 24 mm, 18 mm, green
GTIN (EAN)	4008190493509	
Qty.	100 ST	

Accessories / replacement parts



- Crimping tools for wire end ferrules, with and without plastic collars
- Ratchet guarantees precise crimping
 - Release option in the event of incorrect operation

PZ 6 ROTO L ZERT

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

General ordering data

Type	ERTE ES PZ 6 ROTO L	Version
Order No.	2561810000	
GTIN (EAN)	4050118570199	
Qty.	1 ST	

Replacement parts



After stripping the insulation, a suitable contact or wire end ferrule can be crimped onto the end of the cable. Crimping forms a secure connection between conductor and contact and has largely replaced soldering. Crimping denotes the creation of a homogeneous, permanent connection between conductor and connecting element. The connection can be made only with high-quality precision tools. The result is a secure and reliable connection both in mechanical and electrical terms. Weidmüller offers a wide range of mechanical crimping tools. Integral ratchets with release mechanisms guarantee optimum crimping. Crimped connections made with Weidmüller tools comply with international standards and regulations.

General ordering data

Type	ERTE GRIFFE PZ	Version
Order No.	9202810000	Pressing tool, Replacement part
GTIN (EAN)	4032248512577	
Qty.	1 ST	

Accessories / replacement parts



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Type	ERSATZTEILSET CLIP PZ 6...	Version
Order No.	9054820000	
GTIN (EAN)	4032248109289	
Qty.	1 ST	
Type	ERTE KN SET PZ 6 ROTO L	Version
Order No.	2566680000	
GTIN (EAN)	4050118577105	
Qty.	1 ST	