


## HSS-HF 6.4-12.7 EL B30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

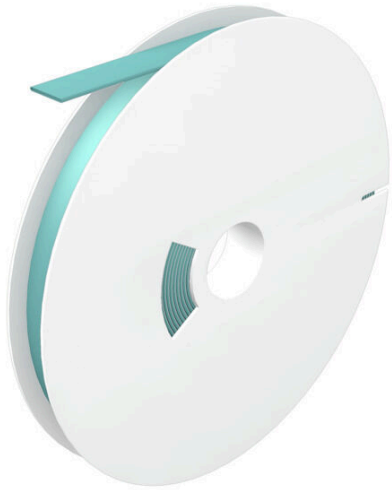

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

### General ordering data

|            |  |
|------------|--|
| Version    | Conductor and cable markers, 6.4 - 12.7 mm, blue |
| Order No.  | <a href="#">1562900000</a>                       |
| Type       | HSS-HF 6.4-12.7 EL B30M                          |
| GTIN (EAN) | 4050118367706                                    |
| Qty.       | 1 items  |

## HSS-HF 6.4-12.7 EL B30M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 1.2 mm   | Depth (inches)  | 0.0472 inch |
| Width      | 20.9 mm  | Width (inches)  | 0.8228 inch |
| Length     | 30000 mm | Length (inches) | 1181.1 inch |
| Net weight | 747 g    |                 |             |

### Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -55...105 °C |
|-----------------------------|--------------|

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### General data

|                                   |              |                                   |  |
|-----------------------------------|--------------|-----------------------------------|--|
| Type of printing                  | neutral      | Width                             | 20.9 mm  |
| Operating temperature range, max. | 105 °C       | Operating temperature range, min. | -55 °C   |
| Colour                            | blue         | Halogen                           | No   |
| Length                            | 30000 mm     | Basic material                    | Polyolefine  |
| Printed characters                | without      | compatible printer                | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> |
| Operating temperature range       | -55...105 °C | Number per roll                   | 1  |

### Conductor and cable markers

|                                   |                        |                               |                    |
|-----------------------------------|------------------------|-------------------------------|--------------------|
| Halogen                           | No                     | Conductor cross-section, max. | 35 mm <sup>2</sup> |
| Conductor cross-section, min.     | 6 mm <sup>2</sup>      | Conductor O.D., max.          | 12.7 mm            |
| Conductor O.D., min.              | 6.4 mm                 | Rate of shrinkage             | 2:1                |
| Recommended shrinking temperature | 90 °C                  | Conductor O.D.                | 6.4 - 12.7 mm      |
| Cross-section for connected wire  | 6 - 35 mm <sup>2</sup> |                               |                    |

 
### Important note

|                     |   |
|---------------------|---|
| Product information | External roll holder 1302920000 necessary |
|---------------------|---|

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |

**Drawings**



## HSS-HF 6.4-12.7 EL B30M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

# Accessories

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

|            |                            |            |
|------------|----------------------------|------------|
| Type       | RIBBON HSS HF EL 40/300... | Version    |
| Order No.  | <a href="#">1426210000</a> | Ink ribbon |
| GTIN (EAN) | 4050118228823              |            |
| Qty.       | 1 ST                       |            |

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

|            |                            |         |
|------------|----------------------------|---------|
| Type       | THM MMP EXT.RH             | Version |
| Order No.  | <a href="#">1302920000</a> |         |
| GTIN (EAN) | 4050118102307              |         |
| Qty.       | 1 ST                       |         |
| Type       | MULTIMARK ROLLER 115       | Version |
| Order No.  | <a href="#">1357420000</a> |         |
| GTIN (EAN) | 4050118160314              |         |
| Qty.       | 1 ST                       |         |
| Type       | MULTIMARK ROLLER 30        | Version |
| Order No.  | <a href="#">1357430000</a> |         |
| GTIN (EAN) | 4050118160253              |         |
| Qty.       | 1 ST                       |         |

## HSS-HF 6.4-12.7 EL B30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK PLUS ROLLER 1... | Version |  |
| Order No.  | <a href="#">2672590000</a> |         |  |
| GTIN (EAN) | 4050118708097              |         |  |
| Qty.       | 1 ST                       |         |  |