


RSV1,6 ZE09 BK BX

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Product image

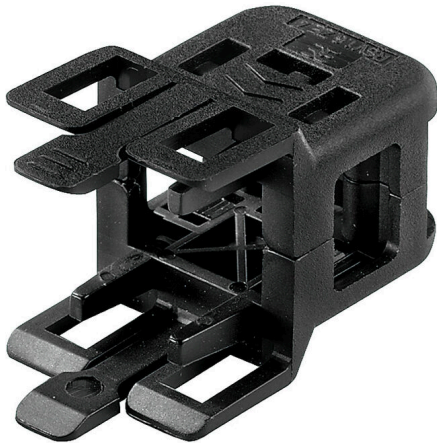

Similar to illustration

For frequent load changes: the "trailer coupling" for plug-in connectors.

The strain relief can do more than just relieve the strain on conductors:

Simply clip onto the plug and

- bundle conductors
- guide cables
- use as a connection and disconnection aid

No damage to the connecting points, clear, tidy wiring and easy to handle.

User advantages: permanent heavy-duty connections for harsh industrial environments and convenient operation ensure improved system availability.

General ordering data

| | |
|--------------|--|
| Version | PCB plug-in connector, Accessories, Strain relief, black, Number of poles: 9 |
| Order No. | 1563400000 |
| Type | RSV1,6 ZE09 BK BX |
| GTIN (EAN) | 4008 190085896 |
| Qty. | 25 items |
| Product data | |
| Packaging | Box |

RSV1,6 ZE09 BK BX

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 7.12 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Material data

| | | | |
|---------------------------------------|----------|---------------------------------------|--------|
| Insulating material | PA | Colour | black |
| Colour chart (similar) | RAL 9011 | Moisture Level (MSL) | |
| Contact material | Cu-alloy | Storage temperature, min. | -40 °C |
| Storage temperature, max. | 70 °C | Operating temperature, min. | -50 °C |
| Operating temperature, max. | 100 °C | Temperature range, installation, min. | -25 °C |
| Temperature range, installation, max. | 100 °C | | |

Rated data acc. to IEC

tested acc. to standard IEC 60664-1, IEC 61984

Packing

| | | | |
|-----------|-----------|------------|-----------|
| Packaging | Box | VPE length | 159.00 mm |
| VPE width | 139.00 mm | VPE height | 62.00 mm |

Important note

IPC conformity Conformity: The products are developed, manufactured and delivered according international recognized standards and norms and comply with the assured properties in the data sheet resp. fulfill decorative properties in accordance with IPC-A-610 "Class 2". Further claims on the products can be evaluated on request.

Notes

- Long term storage of the product with average temperature of 50 °C and maximum humidity 70%, 36 months

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002943 | ETIM 9.0 | EC002943 |
| ETIM 10.0 | EC002943 | ECLASS 14.0 | 27-46-04-02 |
| ECLASS 15.0 | 27-46-04-02 | | |