

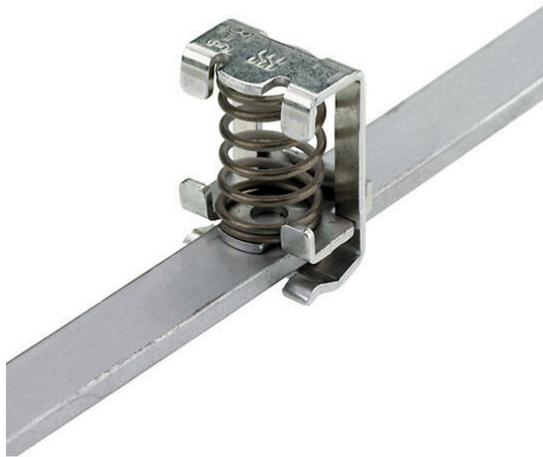
**KLBUE 3-8****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

With our wide range of KLBÜ shield connections, you can achieve flexible and self-adjusting shield contacting and ensure error-free plant operation.

**General ordering data**

Version	Clamping yoke, Clamping yoke for shield connection, Steel
Order No.	<a href="#">1600480000</a>
Type	KLBUE 3-8
GTIN (EAN)	4008190130589
Qty.	10 items

## KLBUE 3-8

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	26 mm	Depth (inches)	1.0236 inch
Height	18.5 mm	Height (inches)	0.7283 inch
Width	14.5 mm	Width (inches)	0.5709 inch
Net weight	9 g		

## Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
Continuous operating temp., min.	-60 °C	Continuous operating temp., max.	130 °C

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	0.056 kg CO2 eq.	

## Material data

Basic material	Steel	Colour	silver
UL 94 flammability rating	None		

## System specifications

Version	For a shield connection	End cover plate required	No
Mounting rail	Busbar		

## Additional technical data

Type of fixing	Snap-on	Installation advice	Busbar
Explosion-tested version	Yes		

## Conductors for clamping (rated connection)

Stripping length	18.5 mm	Type of connection	Spring connection
Number of connections	1	Cable diameter, max.	8 mm
Cable diameter, min.	3 mm	Connection cross-section, stranded, max.	8 mm <sup>2</sup>
Connection cross-section, stranded, min. 3 mm <sup>2</sup>			

## Dimensions

Pitch in mm (P)	13.00 mm
-----------------	----------

## General

Installation advice	Busbar	Mounting rail	Busbar
---------------------	--------	---------------	--------

## Rating data

Rated cross-section	8 mm <sup>2</sup>
---------------------	-------------------

## Technical data

### Classifications

ETIM 8.0	EC002020	ETIM 9.0	EC002020
ETIM 10.0	EC002020	ECLASS 14.0	27-25-01-20
ECLASS 15.0	27-25-01-20		

## KLBU3-8

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Busbars



With our bus bars in various materials and the associated accessories, you can connect cables in the smallest installation space. Depending on the application, potentials can be collected, distributed or dissipated.

### General ordering data

Type	SSCH 10X3X1000 CU/SN	Version	
Order No.	<a href="#">0348900000</a>	Busbar (terminal), silver, Height: 1000 mm, Depth: 3 mm, Copper	
GTIN (EAN)	4008190024802		
Qty.	25 M		

### Accessories



The comprehensive accessories of the Klippon® Connect portfolio are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms

### General ordering data

Type	WSH 1	Version	
Order No.	<a href="#">1068700000</a>	Accessories, Rail support, PA 66 GF 30	
GTIN (EAN)	4008190118389		
Qty.	10 ST		
Type	WSH 5	Version	
Order No.	<a href="#">1080100000</a>	Accessories, Rail support, Wemid	
GTIN (EAN)	4008190965143		
Qty.	10 ST		
Type	WSH 6	Version	
Order No.	<a href="#">1080200000</a>	Accessories, Rail support, Wemid	
GTIN (EAN)	4008190965150		
Qty.	10 ST		
Type	WSH 3/H/N	Version	
Order No.	<a href="#">1715970000</a>	Accessories, Rail support, Wemid	
GTIN (EAN)	4008190353100		
Qty.	10 ST		