


**CC-HO 85/54 SW**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

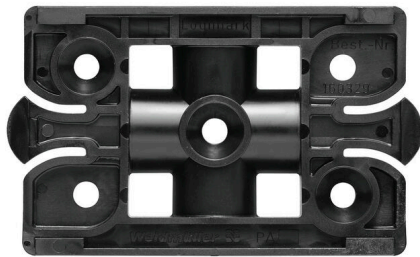

**General ordering data**

Version	ClipCard, Accessories, 90 x 58 mm, black
Order No.	<a href="#">1603290000</a>
Type	CC-HO 85/54 SW
GTIN (EAN)	4008 190188306
Qty.	20 items

## CC-HO 85/54 SW

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	13 mm	Depth (inches)	0.5118 inch
Height	90 mm	Height (inches)	3.5433 inch
Width	58 mm	Width (inches)	2.2835 inch
Net weight	21.15 g		

## Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption	
REACH SVHC	No SVHC above 0.1 wt%	
Product Carbon Footprint	Cradle to gate	0.197 kg CO2 eq.

## General data

Version	Marker holder	
Width	58 mm	
UL 94 flammability rating	V-2	
Operating temperature range, max.	100 °C	
Operating temperature range, min.	-40 °C	
Colour	black	
Halogen	No	
Basic material	Polyamide 66	
Number of markers per packaging unit	Form of supply	MultiCard
Recommended industries	Machinery	
Number of markers per combination	1 MultiCard = Accessories	
Operating temperature range	-40...100 °C	

## Device markers

Halogen	No
---------	----

## Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		