


CC-H 85/54 GR

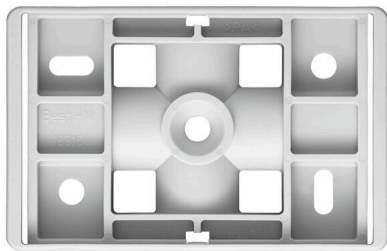

General ordering data

Version	ClipCard, Accessories, 90 x 58 mm, grey
Order No.	1631640002
Type	CC-H 85/54 GR
GTIN (EAN)	4008 19046526 1
Qty.	20 items

CC-H 85/54 GR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	13 mm	Depth (inches)	0.5118 inch
Height	90 mm	Height (inches)	3.5433 inch
Width	58 mm	Width (inches)	2.2835 inch
Length	90 mm	Length (inches)	3.5433 inch
Diameter	0 mm	Net weight	20.9 g

Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	-0.002 kg CO2 eq.	

General data

Material colour according to resistance code	8		
Version	Marker holder		
Width	58 mm		
UL 94 flammability rating	V-2		
Operating temperature range, max.	100 °C		
Operating temperature range, min.	-40 °C		
Colour	grey		
Halogen	No		
Length	90 mm		
Basic material	Polyamide 66		
Number of markers per packaging unit	Form of supply	MultiCard	
Recommended industries	Machinery		
Number of markers per combination	1 MultiCard = Accessories		
Operating temperature range	-40...100 °C		

Device markers

Diameter	0 mm	Halogen	No
----------	------	---------	----

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		