


CC-H 85/54 BG

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

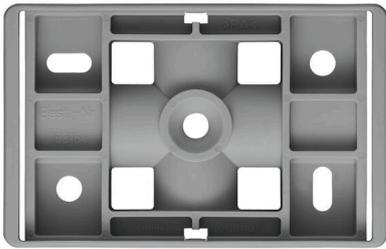

General ordering data

Version	ClipCard, Accessories, 90 x 58 mm, dark beige
Order No.	1631640003
Type	CC-H 85/54 BG
GTIN (EAN)	4008 190465292
Qty.	20 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	13 mm	Depth (inches)	0.5118 inch
Height	90 mm	Height (inches)	3.5433 inch
Width	58 mm	Width (inches)	2.2835 inch
Net weight	25.15 g		

Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	-0.002 kg CO2 eq.	

General data

Version	Marker holder		
Width	58 mm		
UL 94 flammability rating	V-2		
Operating temperature range, max.	100 °C		
Operating temperature range, min.	-40 °C		
Colour	dark beige		
Halogen	No		
Basic material	Polyamide 66		
Number of markers per packaging unit	Form of supply	MultiCard	
Recommended industries	Machinery		
Number of markers per combination	1 MultiCard = Accessories		
Operating temperature range	-40...100 °C		

Device markers

Halogen	No
---------	----

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Accessories

Natural



- CB cable ties for the fastening of cables and markers.
- They are particularly suitable for fastening CLI M, SFX, WKM and WKS cable markers
 - IEC 62275: 2006-conformant
 - Fracture-resistant polyamide PA 6.6 with flammability rating V2 to UL-94

General ordering data

Type	CB 360/4,5 NC	Version	
Order No.	1279000000		Cable ties, 4.5 x 360 mm, Polyamide 66, 220 N
GTIN (EAN)	4008190031459		
Qty.	100 ST		
Type	CB 365/7,5 NC	Version	
Order No.	1279100000		Cable ties, 7.5 x 365 mm, Polyamide 66, 540 N
GTIN (EAN)	4008190104665		
Qty.	100 ST		