

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Installation size: 8, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, End-locking clamp, lower side, high, Size of cable entries: PG 21
Order No.	1662610000
Type	HDC 64D TOLU 1PG21G
GTIN (EAN)	4008190419134
Qty.	1 items

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E92202

Dimensions and weights

Height	76 mm	Height (inches)	2.9921 inch
Width	45.5 mm	Width (inches)	1.7913 inch
Net weight	333 g		

Temperatures

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%
Chemical resistance	Substance Acetone
	Chemical resistance Conditionally resistant
	Substance Drilling oil
	Chemical resistance Resistant
	Substance Diesel
	Chemical resistance Resistant
	Substance Ethyl alcohol
	Chemical resistance Resistant
	Substance Transmission oil
	Chemical resistance Resistant
	Substance Hydraulic oil
	Chemical resistance Resistant
	Substance Coolant
	Chemical resistance Resistant
	Substance Petroleum benzine
	Chemical resistance Resistant
	Substance Sweat
	Chemical resistance Resistant
	Substance Premium gasoline
	Chemical resistance Conditionally resistant
	Substance Water
	Chemical resistance Resistant
	Substance UV
	Chemical resistance Unstable
	Substance Ozone
	Chemical resistance Unstable

Dimensions

Cable entry	w. thread	Width housing C	43 mm
Total length housing	120 mm	Height of housing B	76 mm

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

General data

Housing main material	diecast aluminium
Protection degree	IP65, in plugged condition
Material of locking element	Stainless steel, rust-proof

Surface finish	Powder coating
EMC housings	No

Version

Size of cable entries	PG 21
Cover	without cover
Number of cable entry sideways	0
Design of locking system	End-locking clamp, lower side
Installation size	8
Type	Plug
Sealing	no sealing
Colour (RAL)	RAL 7035
Suitable for ModuPlug®	Yes

Top part/bottom part/lid	upper part
Number of cable entry on top	1
Design of housing	Cable entry from top, Plug housing
Design	high
Cable entry	w. thread
Clamp version	End-locking clamp
Internal thread	PG 21
BG	8

Classifications

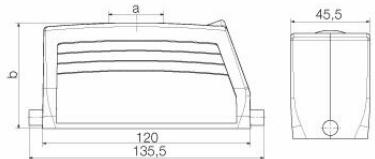
ETIM 8.0	EC000437
ETIM 10.0	EC000437
ECLASS 15.0	27-44-02-02

ETIM 9.0	EC000437
ECLASS 14.0	27-44-02-02

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B SLDU 2PG21G	Version
Order No.	1214500000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190153021	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: PG 21
Type	HDC 24B SLU 2PG21G	Version
Order No.	1662720000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190419240	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: PG 21
Type	HDC 64D SLDU 2PG29G	Version
Order No.	1663040000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190419561	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: PG 29
Type	HDC 64D SLU 2M32G	Version
Order No.	1786900000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204144	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 32
Type	HDC 64D SLU 2M25G	Version
Order No.	1786910000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204151	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 25
Type	HDC 64D SLDU 2M32G	Version
Order No.	1786940000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204182	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 32
Type	HDC 64D SLDU 2M25G	Version
Order No.	1786950000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248204199	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 25
Type	HDC 24B SLU 2M25G	Version
Order No.	1787880000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248205325	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
Klingenbergsstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Type	HDC 24B SDLU 2M25G	Version
Order No.	1787900000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248205349	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: M 25
Type	HDC 24B SDLU 1M25G	Version
Order No.	1901480000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248521364	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: M 25
Type	HDC 24B SLU 1M25G	Version
Order No.	1901560000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248521395	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25
Type	HDC 64D SDLU 1M25G	Version
Order No.	1904430000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585106	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 25
Type	HDC 64D SDLU 1M32G	Version
Order No.	1904440000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585212	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	with cover, Size of cable entries: M 32
Type	HDC 64D SLU 1M25G	Version
Order No.	1904480000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585090	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 25
Type	HDC 64D SLU 1M32G	Version
Order No.	1904490000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248585618	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	Size of cable entries: M 32

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B ALU	Version
Order No.	1213900000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190176303	plugged condition, Bulkhead housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: none

HDC 64D TOLU 1PG21G

Weidmüller Interface GmbH & Co. KG
 Klingenbergsstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Type	HDC 24B ADLU	Version
Order No.	1214300000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4008190083090	plugged condition, Bulkhead housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, with cover, Size of cable entries: none

Coupling hood

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B KLU 1M25G	Version
Order No.	1968340000	HDC enclosures, Installation size: 8, Protection degree: IP65, in
GTIN (EAN)	4032248689378	plugged condition, Coupling housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: M 25