

HDC 06B DODL 2B0**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Version	HDC enclosures, Installation size: 3, Protection degree: IP65, in plugged condition, Cover for lower part of housing, End-locking clamp, lower side, Standard
Order No.	1665200000
Type	HDC 06B DODL 2B0
GTIN (EAN)	4008190421908
Qty.	1 items

HDC 06B DODL 2BO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E92202

Dimensions and weights

Height	18 mm	Height (inches)	0.7087 inch
Width	43 mm	Width (inches)	1.6929 inch
Net weight	58 g		

Temperatures

Limit temperature -40 °C ... 125 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Chemical resistance

Substance	Acetone
Chemical resistance	Conditionally resistant
Substance	Drilling oil
Chemical resistance	Resistant
Substance	Diesel
Chemical resistance	Resistant
Substance	Ethyl alcohol
Chemical resistance	Resistant
Substance	Transmission oil
Chemical resistance	Resistant
Substance	Hydraulic oil
Chemical resistance	Resistant
Substance	Coolant
Chemical resistance	Resistant
Substance	Petroleum benzine
Chemical resistance	Resistant
Substance	Sweat
Chemical resistance	Resistant
Substance	Premium gasoline
Chemical resistance	Conditionally resistant
Substance	Water
Chemical resistance	Resistant
Substance	UV
Chemical resistance	Unstable
Substance	Ozone
Chemical resistance	Unstable

Dimensions

Cable entry	For bases	Width housing C	43 mm
Total length housing	60 mm	Height of housing B	18 mm

HDC 06B DODL 2BO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

General data

Tightening torque	1.2 Nm	Housing main material	diecast aluminium
Surface finish	Powder coating	Protection degree	IP65, in plugged condition
EMC housings	No	Material of locking element	Stainless steel, rust-proof


Version

Top part/bottom part/lid	Cover	Tightening torque	1.2 Nm
Design of housing	Cover for lower part of housing	Design of locking system	End-locking clamp, lower side
Design	Standard	Installation size	3
Cable entry	For bases	Type	Cover
Clamp version	End-locking clamp	Colour (RAL)	RAL 7035
BG	3	Suitable for ModuPlug®	Yes

Classifications

ETIM 6.0	EC000437	ETIM 7.0	EC000437
ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 9.0	27-44-02-02
ECLASS 9.1	27-44-02-02	ECLASS 10.0	27-44-02-02
ECLASS 11.0	27-44-02-02	ECLASS 12.0	27-44-02-02
ECLASS 13.0	27-44-02-02	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

Drawings

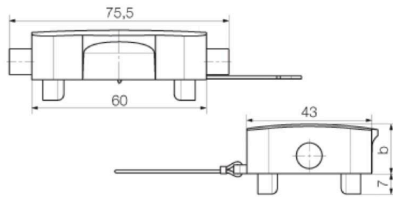

HDC 06B DODL 2B0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmuller.com

Accessories

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 06B SLU 1M20G	Version
Order No.	1900460000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248585939	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: M 20
Type	HDC 06B SLU 1M25G	Version
Order No.	1900480000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248585946	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: M 25
Type	HDC 06B SLU 1M25G N	Version
Order No.	2560710000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4050118673272	plugged condition, Base housing, End-locking clamp, lower side, ,
Qty.	1 ST	without cover, Size of cable entries: M 25
Type	HDC 06B SLU 1PG16G	Version
Order No.	1652750000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190402822	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: PG 16
Type	HDC 06B SLU 1PG16G N	Version
Order No.	2560840000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4050118673074	plugged condition, Base housing, End-locking clamp, lower side, ,
Qty.	1 ST	without cover, Size of cable entries: PG 16
Type	HDC 06B SLU 2M20G	Version
Order No.	1788140000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248205585	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: M 20
Type	HDC 06B SLU 2M20G N	Version
Order No.	2560850000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4050118673081	plugged condition, Base housing, End-locking clamp, lower side, ,
Qty.	1 ST	without cover, Size of cable entries: M 20
Type	HDC 06B SLU 2M25G	Version
Order No.	1788130000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248205578	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: M 25

HDC 06B DODL 2B0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	HDC 06B SLU 2M25G N	Version
Order No.	2560860000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4050118673098	plugged condition, Base housing, End-locking clamp, lower side, ,
Qty.	1 ST	without cover, Size of cable entries: M 25
Type	HDC 06B SLU 2PG16G	Version
Order No.	1652760000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190402839	plugged condition, Base housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, without cover, Size of cable entries: PG 16
Type	HDC 16D SLU 1M25G	Version
Order No.	1900880000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248521111	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	without cover, Size of cable entries: M 25
Type	HDC 16D SLU 2PG21G	Version
Order No.	1652840000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190402914	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	without cover, Size of cable entries: PG 21
Type	HDC 16D SLU 2M32G	Version
Order No.	1787510000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248204854	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	without cover, Size of cable entries: M 32
Type	HDC 16D SLU 2M25G	Version
Order No.	1787520000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248204861	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	without cover, Size of cable entries: M 25
Type	HDC 16D SLU 1M32G	Version
Order No.	1900900000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248521128	plugged condition, Base housing, End-locking clamp, lower side, high,
Qty.	1 ST	without cover, Size of cable entries: M 32

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 06B ALU	Version
Order No.	1202100000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190149369	plugged condition, Bulkhead housing, End-locking clamp, lower side,
Qty.	1 ST	Side-locking clamp not replaceable, Standard

HDC 06B DODL 2BO

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 06B KLU 1M25G	Version
Order No.	1021330000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4032248734948	plugged condition, Coupling housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: 1*M25
Type	HDC 06B KLU 1PG16G	Version
Order No.	1653200000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190403270	plugged condition, Coupling housing, End-locking clamp, lower side,
Qty.	1 ST	Standard, Size of cable entries: PG 16
Type	HDC 16D KLU 1PG21G	Version
Order No.	1653230000	HDC enclosures, Installation size: 3, Protection degree: IP65, in
GTIN (EAN)	4008190403300	plugged condition, Coupling housing, End-locking clamp, lower side,
Qty.	1 ST	high, Size of cable entries: PG 21