

## HDC 32A DODQ 4B0

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

### General ordering data

Version	HDC enclosures, Installation size: 7, Protection degree: IP65, in plugged condition, Cover for lower part of housing, Side-locking clamp on lower side, Standard, Size of cable entries: none
Order No.	<a href="#">1665920000</a>
Type	HDC 32A DODQ 4B0
GTIN (EAN)	4008190422950
Qty.	1 items

**HDC 32A DODQ 4BO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (cURus)	E92202

**Dimensions and weights**

Depth	82 mm	Depth (inches)	3.2283 inch
Height	17 mm	Height (inches)	0.6693 inch
Width	68 mm	Width (inches)	2.6772 inch
Net weight	82 g		

**Temperatures**

Limit temperature	-40 °C ... 125 °C
-------------------	-------------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption	
REACH SVHC	No SVHC above 0.1 wt%	
Chemical resistance	Substance	Acetone
	Chemical resistance	Conditionally resistant
	Substance	Drilling oil
	Chemical resistance	Resistant
	Substance	Diesel
	Chemical resistance	Resistant
	Substance	Ethyl alcohol
	Chemical resistance	Resistant
	Substance	Transmission oil
	Chemical resistance	Resistant
	Substance	Hydraulic oil
	Chemical resistance	Resistant
	Substance	Coolant
	Chemical resistance	Resistant
	Substance	Petroleum benzine
	Chemical resistance	Resistant
	Substance	Sweat
	Chemical resistance	Resistant
	Substance	Premium gasoline
	Chemical resistance	Conditionally resistant
Substance	Water	
Chemical resistance	Resistant	
Substance	UV	
Chemical resistance	Unstable	
Substance	Ozone	
Chemical resistance	Unstable	

**Dimensions**

Cable entry	For bases	Width housing C	56 mm
Total length housing	82 mm	Height of housing B	17 mm

**HDC 32A DODQ 4B0**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**General data**

Surface finish	Powder coating	Protection degree	IP65, in plugged condition
----------------	----------------	-------------------	----------------------------

**Version**

Size of cable entries	none	Top part/bottom part/lid	Cover
Cover	with cover	Tightening torque	1.2 Nm
Number of cable entry sideways	0	Design of housing	Cover for lower part of housing
Design of locking system	Side-locking clamp on lower side	Design	Standard
Installation size	7	Cable entry	For bases
Type	Cover	Clamp version	Side-locking clamp
Colour (RAL)	RAL 7035	BG	7
Suitable for ModuPlug®	No		

**Classifications**


ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

**HDC 32A DODQ 4B0**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

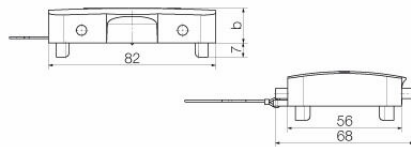

**HDC 32A DODQ 4BO**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Bulkhead housing**



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.  
 The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.  
 The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.  
 The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.  
 Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Type	HDC 32A ABU	Version	
Order No.	<a href="#">1665860000</a>		HDC enclosures, Installation size: 7, Protection degree: IP65, in
GTIN (EAN)	4008190871253		plugged condition, Bulkhead housing, Side-locking clamp on lower
Qty.	1 ST		side, Standard, Size of cable entries: none

**Base housing**



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.  
 The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.  
 The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.  
 The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.  
 Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

Type	HDC 32A SBU 1M25G	Version	
Order No.	<a href="#">1903870000</a>		HDC enclosures, Installation size: 7, Protection degree: IP65, in
GTIN (EAN)	4032248586110		plugged condition, Base housing, Side-locking clamp on lower side,
Qty.	1 ST		Standard, Size of cable entries: M 25
Type	HDC 32A SBU 1PG29G	Version	
Order No.	<a href="#">1666010000</a>		HDC enclosures, Installation size: 7, Protection degree: IP65, in
GTIN (EAN)	4008190423049		plugged condition, Base housing, Side-locking clamp on lower side,
Qty.	1 ST		Standard, Size of cable entries: PG 29

## HDC 32A DODQ 4B0

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	HDC 32A SBU 2M25G	Version
Order No.	<a href="#">1788040000</a>	HDC enclosures, Installation size: 7, Protection degree: IP65, in plugged condition, Base housing, Side-locking clamp on lower side,
GTIN (EAN)	4032248205486	Standard, Size of cable entries: M 25
Qty.	1 ST	
Type	HDC 32A SBU 2PG21G	Version
Order No.	<a href="#">1665980000</a>	HDC enclosures, Installation size: 7, Protection degree: IP65, in plugged condition, Base housing, Side-locking clamp on lower side,
GTIN (EAN)	4008190423018	Standard, Size of cable entries: PG 21
Qty.	1 ST	

## Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

Type	HDC 32A KBU 1M25G	Version
Order No.	<a href="#">1788080000</a>	HDC enclosures, Installation size: 7, Protection degree: IP65, in plugged condition, Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205523	
Qty.	1 ST	
Type	HDC 32A KBU 1M32G	Version
Order No.	<a href="#">1788070000</a>	HDC enclosures, Installation size: 7, Protection degree: IP65, in plugged condition, Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 32
GTIN (EAN)	4032248205516	
Qty.	1 ST	