


ESO 5 P DIN A4 GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

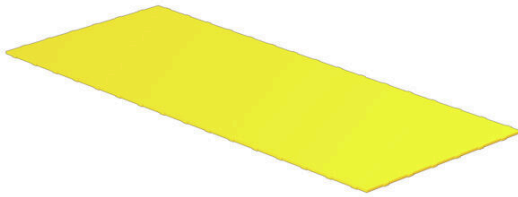

General ordering data

Version	Terminal markers, Insert markers, 40 x 16.5 mm, yellow
Order No.	1670380000
Type	ESO 5 P DIN A4 GE
GTIN (EAN)	4008190430702
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2026-01-31T00:00:00+01:00
Alternative product	ELS 16/40 MM GE

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	1 mm	Depth (inches)	0.0394 inch
Height	40 mm	Height (inches)	1.5748 inch
Width	16.5 mm	Width (inches)	0.6496 inch
Net weight	13.7 g		

Temperatures

Operating temperature range	-40...80 °C
-----------------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Material colour according to resistance code	4		
Orientation of print	horizontal and vertical		
Number per sheet	60		
Width	16.5 mm		
UL 94 flammability rating	HB		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-40 °C		
Colour	yellow		
Basic material	Polyester, PVC-free		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Label sheet	
Number of markers per combination	1 Label sheet = Insert markers		
Operating temperature range	-40...80 °C		

Classifications

ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		

Drawings

