


ESO 7 P DIN A4 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

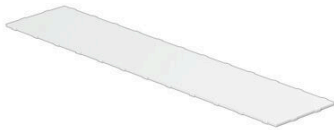

Similar to illustration

General ordering data

Version	Terminal markers, Insert markers, 27 x 6.3 mm, white
Order No.	1670390000
Type	ESO 7 P DIN A4 WS
GTIN (EAN)	4008190430719
Qty.	10 items

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	1 mm	Depth (inches)	0.0394 inch
Height	27 mm	Height (inches)	1.063 inch
Width	6.3 mm	Width (inches)	0.248 inch
Net weight	11.35 g		

Temperatures

Operating temperature range -40...80 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Material colour according to resistance code	9		
Orientation of print	horizontal and vertical		
Number per sheet	240		
Width	6.3 mm		
UL 94 flammability rating	HB		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-40 °C		
Colour	white		
Basic material	Polyester, PVC-free		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Label sheet	
Number of markers per combination	1 Label sheet = Insert markers		
Operating temperature range	-40...80 °C		

Classifications

ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		

Drawings

