


## ESO 7 P DIN A4 GE

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

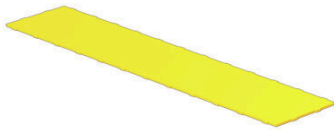

Similar to illustration

### General ordering data

Version	Terminal markers, Insert markers, 27 x 6.3 mm, yellow
Order No.	<a href="#">1670400000</a>
Type	ESO 7 P DIN A4 GE
GTIN (EAN)	4008190430726
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2026-01-30T00:00:00+01:00
Alternative product	<a href="#">THM ESO 7 PA GE</a>

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	1 mm	Depth (inches)	0.0394 inch
Height	27 mm	Height (inches)	1.063 inch
Width	6.3 mm	Width (inches)	0.248 inch
Net weight	11.35 g		

**Temperatures**

Operating temperature range -40...80 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Material colour according to resistance code	4		
Orientation of print	horizontal and vertical		
Number per sheet	240		
Width	6.3 mm		
UL 94 flammability rating	HB		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-40 °C		
Colour	yellow		
Basic material	Polyester, PVC-free		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Label sheet	
Number of markers per combination	1 Label sheet = Insert markers		
Operating temperature range	-40...80 °C		

**Classifications**

ETIM 8.0	EC000761	ETIM 9.0	EC000761
ETIM 10.0	EC000761	ECLASS 14.0	27-28-11-01
ECLASS 15.0	27-28-11-01		

**Drawings**

